

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [2196552105](#)
Status: **Active**
Overview: [Off-the-Shelf Pre-Crimped Leads](#)
Description: Pre-Crimped Lead Micro-One Female-to-Pigtail, Matte Tin Plating, 450.00mm Length, 26 AWG, Red

Documents:

[Drawing \(PDF\)](#)

[Datasheet \(PDF\)](#)

[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Cable Assemblies
Series	219655
Application	Signal, Wire-to-Board
Assembly Configuration	Pre-crimped Lead Only
Connector to Connector	Micro-One-to-Pigtail
Overview	Off-the-Shelf Pre-Crimped Leads
Product Name	Micro-One
Taxonomy	Power and Signal Cable Assembl
UPC	195842804012

Physical

Cable Length	450.00mm
Circuits (Loaded)	1
Color - Resin	Red
Gender	Female-Pigtail
Material - Metal	Copper Alloy
Material - Plating Mating	Matte Tin
Net Weight	1.351/g
Packaging Type	Bag
Plating min - Mating	0.900µm
Plating min - Termination	0.900µm
Single Ended	Yes
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	0.88-1.30mm
Wire Size AWG	26
Wire/Cable Type	UL 1569


Electrical

Current - Maximum per Contact	3.5A
Voltage - Maximum	250V AC (RMS)/DC

Material Info

Reference - Drawing Numbers

Sales Drawing	2196551101-000
---------------	----------------

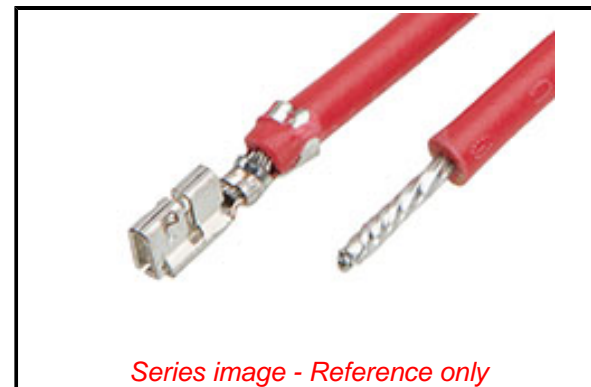

Series image - Reference only

EU ELV

Not Relevant

EU RoHS

Compliant

REACH SVHC

Not Contained per -
D(2022)9120-DC (17
Jan 2023)

Halogen-Free

Status

Not Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Not Relevant

Not Contained

Search Parts in this Series

[219655](#) Series

Use With

Micro-One Receptacle Housing [205979](#) ,
[212724](#)