

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [0347910021](#)
Status: **Active**
Overview: [Mini50 Connection Systems](#)
Description: Mini50 Unsealed Receptacle, Single Row, Bridged, 2 Circuits, Polarization Option B, Gray

Documents:

Drawing (PDF)	Application Specification AS-34791-020-CH-001 (PDF)
3D Model	Test Summary 347910020-TS-000 (PDF)
3D Model (PDF)	Datasheet (PDF)
Product Specification PS-34791-020-001 (PDF)	RoHS Certificate of Compliance (PDF)
Application Specification AS-34791-020-001 (PDF)	

General

Product Family	Crimp Housings
Series	34791
Application	Automotive, Power, Wire-to-Board
Overview	Mini50 Connection Systems
Polarization	B
Product Name	Mini50
Taxonomy	Connector Housings
UPC	889056527545


Physical

Circuits (maximum)	2
Color - Resin	Gray
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	PBT
Net Weight	0.540/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	AS-34791-020-001, AS-34791-020-CH-001
Product Specification	PS-34791-020-001
Sales Drawing	SD-34791-001-000
Test Summary	347910020-TS-000

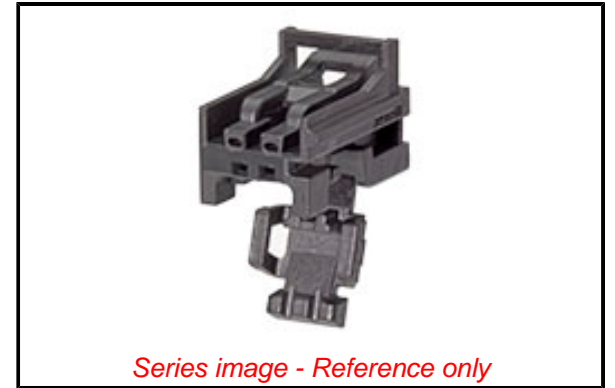

Series image - Reference only

EU ELV

Compliant

EU RoHS

Compliant

REACH SVHC

Not Contained per -
D(2022)9120-DC (17
Jan 2023)

Halogen-Free

Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

China RoHS

Green Image

Compliant

Not Contained

Search Parts in this Series

[34791 Series](#)

Mates With

[Mini50 Right-Angle Surface Mount Header 34912](#) . [Mini50 Inline Plug 2037000021](#)

Use With

[CTX50 Unsealed Terminals 560023](#)