

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

0349590342

Status:


Active

Overview:

Mini50 Connection Systems

Description:

Mini50 Unsealed Receptacle, 3 Rows, with CPA, 34 Circuits, Polarization Option C, Dark Gray

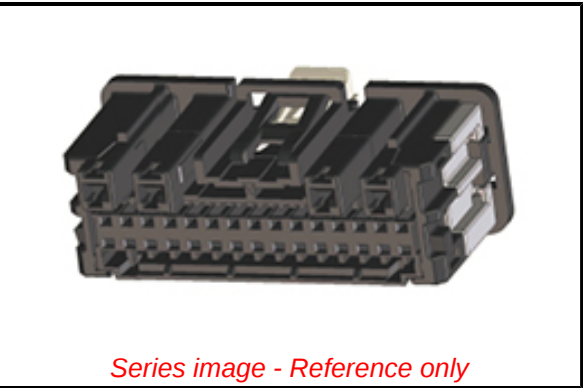

- Documents:
- Drawing (PDF)

3D Model (PDF)

3D Model

Product Specification PS-34959-001-001 (PDF)

Application Specification 349590001-AS-CH-000 (PDF)

Application Specification AS-34959-001-001 (PDF)

Test Summary TS-34961-001-001 (PDF)

Datasheet (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Crimp Housings
Series	34959
Application	Automotive, Power, Wire-to-Board
Overview	Mini50 Connection Systems
Polarization	C
Product Name	Mini50
Taxonomy	Connector Housings
UPC	887191704432
Physical	
Circuits (maximum)	34
Color - Resin	Gray (Dark)
Gender	Receptacle
Glow-Wire Capable	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	5.522/g
Number of Rows	3
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Pitch - Termination Interface	2.00mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40° to +105°C

Material Info

Reference - Drawing Numbers

Application Specification	349590001-AS-CH-000, AS-34959-001-001
Product Specification	PS-34959-001-001
Sales Drawing	SD-34959-030-001
Test Summary	TS-34961-001-001

EU ELV
Compliant

EU RoHS
Compliant

China RoHS

REACH SVHC

Not Contained per -
D(2022)9120-DC (17
Jan 2023)

Halogen-Free
Status

Low-Halogen

For more information, please visit [Contact US](#)

China ROHS	Green Image
ELV	Compliant
RoHS Phthalates	Not Contained

Search Parts in this Series
34959 Series

Mates With

Mini50 Vertical Headers:
 [349580342](#)
, [349587342](#) , [349588342](#)
Mini50
Right-Angle Headers:
 [349610342](#) ,
[349617342](#) , [349618342](#)

Use With

CTX50 Unsealed Terminals [560023](#)