



Twister® Wire Connectors

- *Exceptional wire-range capacity: #22 to #8 AWG*
- *Fast, secure connections every time*
- *Compact, comfortable swept-wing design*



Made in U.S.A. of
U.S. and Global
Components









Twister® Wire Connector


IDEAL Twister® Wire Connectors were designed with the features electricians want most.

Twister® Wire Connectors feature a swept-wing design that fits comfortably in your hand and provides improved leverage and greater torque. The live-action, square-wire spring provides fast, secure connections every time. Two sizes handle 95% of all typical branch-circuit wire combinations – from a minimum of 2 #22 AWG to a maximum of 2 #8 with 2 #12 AWG. This means fewer connector models to carry at the jobsite, reduced inventory and lower total cost.

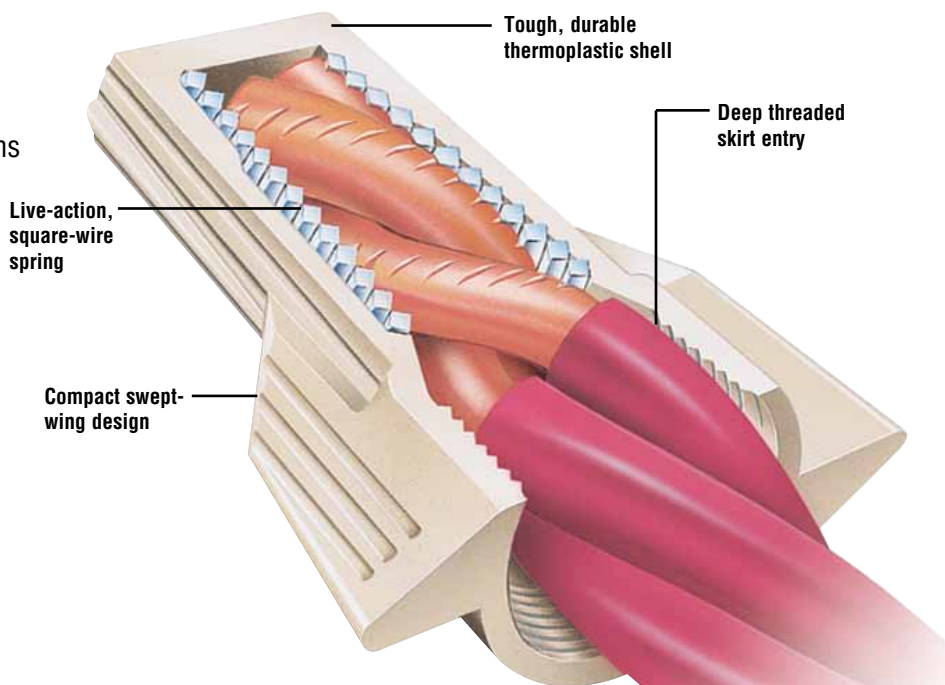- Exceptional wire-range capacity – three models handle conductors from #22 to #6 AWG
- Swept-wing design provides improved leverage with less effort, especially on larger combinations
- The square-wire spring picks up fast and provides secure connections
- Hex-top allows installation using standard nutdriver.
- Ribbed shell provides added grip and fast fingertip starts
- Deep skirt protects against flash-over and turned-back strands for maximum dielectric strength
- Tough, UL 94V-2 flame-retardant shell will not crack – even when applied to maximum wire combinations. Rated at 105°C (221°F)



Model No.	Wire Range (in.)	Wire Range (mm)	Qty.	Cat. No.
 340® Lite Blue	600V* 22 to 10 AWG Min. 2 #22 Max. 3 #12	600V* ,34mm ² to 4,0mm ² DIA Min. 2-,34mm ² Max. 3-4,0mm ²	Box of 100	30-340
			Jar of 500	30-640J
			Barrel of 35,000	30-840
 341® Tan	600V* 22 to 8 AWG Min. 3 #22 Max. 3 #10	600V* ,34mm to 10,00mm ² DIA Min. 3-,34mm ² Max. 3-6,0mm ²	Box of 100	30-341
			Jar of 400	30-441J
			Jar of 750	30-341J
			Keg of 5,000 (10 bags, 500 ea.)	30-641
 342® Gray	600V* 18 to 6 AWG Min. 3 #14 Max. 2 #8 w/2 #12	600V* ,75mm ² to 10,0mm ² DIA Min. 3-2,5mm ² Max. 2-10,00mm ² w/2-4,0mm ²	Barrel of 25,000	30-841
			Box of 50	30-342
			Keg of 2,500 (10 bags, 250 ea.)	30-642
			Barrel of 15,000	30-842

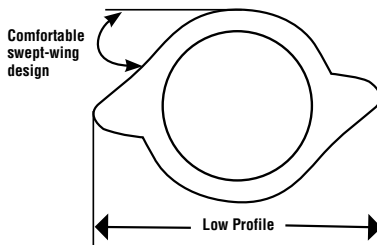

*1,000 Volts maximum in fixtures and signs.

IDEAL INDUSTRIES, INC.

Becker Place, Sycamore, IL 60178, USA / 815-895-5181 • 800-435-0705 in USA

International offices:

Australia • Brazil • Canada • China • Germany • Mexico • UK

For complete sales office contact information, visit us at:

www.idealind.com