
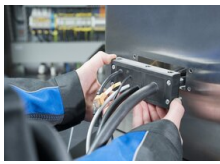


VarioPlate Blindplug 7-9 mm

Art.-No. 440-00043 | VP_7-9_Blindplug-PL-BK | [Details](#)

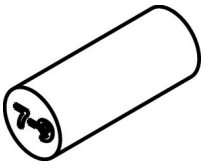

- Blind grommets are needed to replace the cable grommets that are not equipped with wires
- The IP protection class is retained

HF ✓

RoHS ✓


More products in this product group:

[VarioPlate Cable Entry System >](#)

Base Data

Cable Ø max	9.0 mm
Cable Ø min	7.0 mm
Colour	Black (BK)
Description	VarioPlate Blindplug 7-9 mm
Material	Plastic (PL)
Pack Content	20 pcs.
Package Content packed in	bag
PART DESCRIPTION	VP_7-9_Blindplug-PL-BK
Product Family	VarioPlate Blindplug 7-9 mm
Product Group	VarioPlate Cable Entry System
Variant	Both sides open

Product Dimensions

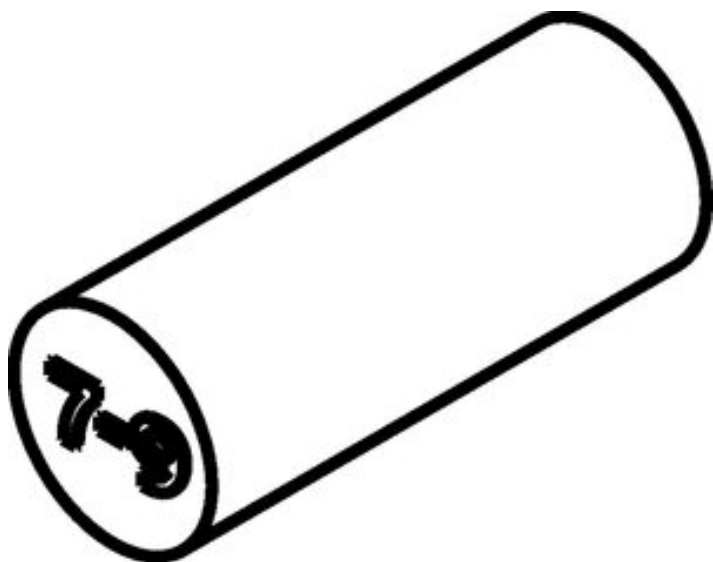

Depth (D)	20 mm
Height (H)	11 mm
Width (W)	7 mm

Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 V0
Halogen-free	Yes
Hazardous good	No
IP-Rating	IP66
Operating Temperature	-40 °C to +100 °C
Self extinguishing (Yes/No)	Yes
Specifications	HF✓ RoHS✓

Logistics and Packaging

GTIN-13 / EAN	4031026686349
Packaging 1 - Height (m)	0.005 m
Packaging 1 - Length (m)	0.19 m
Packaging 1 - Qty	20
Packaging 1 - Type	bag
Packaging 1 - Volume (m³)	0.00011 m³
Packaging 1 - Weight (kg)	0.02 kg
Packaging 1 - Width (m)	0.12 m
Packaging 2 - Height (m)	0.216 m
Packaging 2 - Length (m)	0.3048 m
Packaging 2 - Type	carton
Packaging 2 - Volume (m³)	0.0176 m³
Packaging 2 - Width (m)	0.267 m

More Information

Subscribe to our newsletter >

