Pushbutton Switch
Snap-Acting, Sealed

multicomp PRO

RoHS Compliant

Specifications

Material

Movable Contact : Copper Alloy, Silver Plated
Terminal : Copper Alloy, Silver Plated with outer in gold plating

Electrical

Voltage Rating : 120V AC or 38V DC
Current Rating : 1 Amps
Contact Resistance : 10mΩ max.
Insulation Resistance : 1000MΩ min.
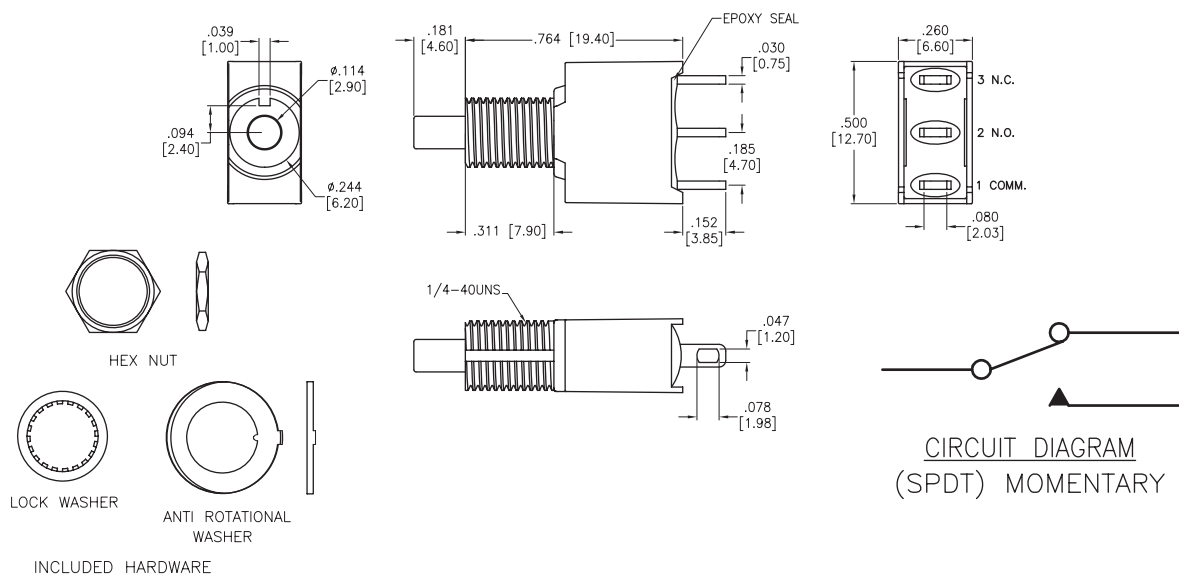Dielectric withstanding Voltage : 1500V RMS @ sea level

Mechanical

Waterproof : IP68

Temperature Rating

Operating temperature : -30°C to +85°C

Diagram

HEX NUT

LOCK WASHER

ANTI ROTATIONAL WASHER

INCLUDED HARDWARE

CIRCUIT DIAGRAM
(SPDT) MOMENTARY

Dimensions : Millimetres

Part Number Table

Description	Part Number
Pushbutton Switch, SPDT, On-MOM, Solder Type	MP-PB8-AA00A1GE-2

multicomp PRO