


**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [2159131004](#)  
**Status:** **Active**  
**Overview:** [Mini-Fit Family Power Connectors](#)  
**Description:** Mini-Fit Max Receptacle Housing, Single Row, UL 94V-0, 4 Circuits, Glow-Wire Capable, Black

**Documents:**

<a href="#">Drawing (PDF)</a>	<a href="#">Test Summary 2125150000-TS-000 (PDF)</a>
<a href="#">Product Specification 2125150000-PS-000 (PDF)</a>	<a href="#">Datasheet (PDF)</a>
<a href="#">Packaging Specification 2125140001-PK-000 (PDF)</a>	<a href="#">RoHS Certificate of Compliance (PDF)</a>

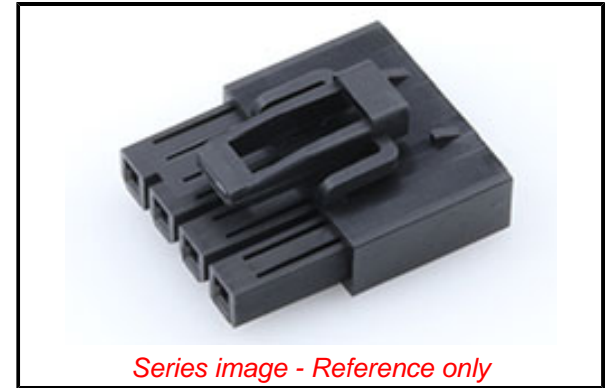

**Agency Certification**

UL E29179

**General**

Product Family	Crimp Housings
Series	<a href="#">215913</a>
Application	Power, Wire-to-Board, Wire-to-Wire
Overview	<a href="#">Mini-Fit Family Power Connectors</a>
Product Name	Mini-Fit Max
Taxonomy	Connector Housings
UPC	195842607934

**Physical**

Circuits (maximum)	4
Color - Resin	Black
Flammability	94V-0
Gender	Receptacle
Glow-Wire Capable	Yes
Keying to Mating Part	None
Lock to Mating Part	Yes
Material - Resin	Nylon
Net Weight	1.232/g
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	4.20mm
Pitch - Termination Interface	4.20mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40° to +105°C

**Material Info**

**Reference - Drawing Numbers**

Packaging Specification	2125140001-PK-000
Product Specification	2125150000-PS-000
Sales Drawing	2159130000-SD-000
Test Summary	2125150000-TS-000

**EU ELV**

**Not Relevant**

**EU RoHS**

**Compliant**

**REACH SVHC**

Not Contained per -  
D(2022)9120-DC (17  
Jan 2023)

**Halogen-Free**

**Status**

**Not Low-Halogen**

For more information, please visit [Contact US](#)

China ROHS

ELV

RoHS Phthalates

**China RoHS**

Green Image

Not Relevant

Not Contained

**Search Parts in this Series**

[215913 Series](#)

**Mates With**

Mini-Fit Max Header [215915](#)

**Use With**

Mini-Fit Max Crimp Terminal [212515](#) . Mini-Fit Max TPA [212516](#)