


Part-No. 244628-E



# SMC Board-on

12-pin, SMT/IDC

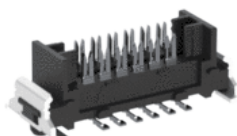

## Technical Data

Applications	Cable Connectors, PCB Connectors,
Pitch	1.27 mm
No. of Pins	12
Termination	SMT/IDC
Current Rating	1.8 A
Max Operating Temperature	105 °C
Data Rate	3 Gbit/s
Air- and creepage distance	0.4 mm
Mating Cycles	500
Configuration	Connector
Packaging	Tape and reel 600 pcs

Part-No. 244628-E

## **SMC Board-on**

**12-pin, SMT/IDC**