


Part-No. 244856-E



SMC Male Connector

50-pin, vertical, SMT

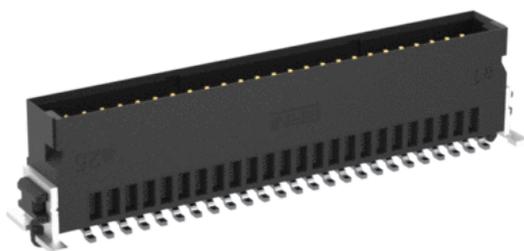

Technical Data

Applications	PCB Connectors, ,
Pitch	1.27 mm
Orientation	Vertical
Gender	Male
No. of Pins	50
Termination	SMT
Current Rating	1.1 A
Max Operating Temperature	125 °C
Data Rate	3 Gbit/s
Air- and creepage distance	0.4 mm
Mating Cycles	500

Unmated Stacking Height	3.25 mm
Packaging	Tape and reel 280 pcs

Part-No. 244856-E

SMC Male Connector

50-pin, vertical, SMT