


SLB2-R

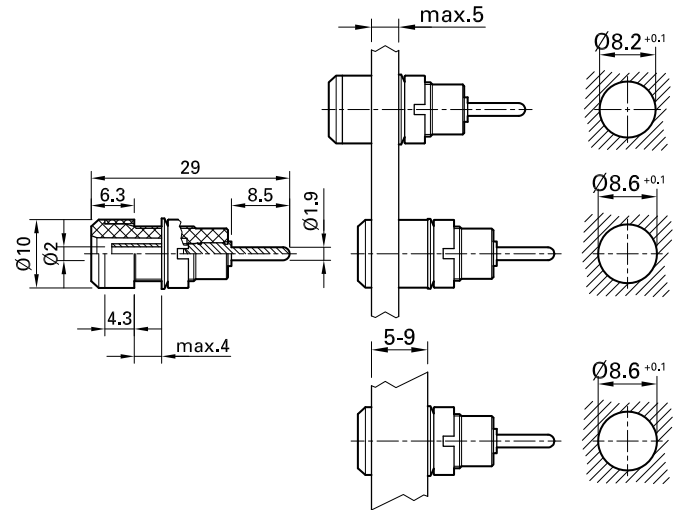

Item number 65.9194-*

Insulated, rigid, accepting spring-loaded Ø 2 mm plugs with rigid insulating sleeve. The socket is surface-mounted or assembled flush into pre-drilled panels of plastic, metal, etc. Round connecting pin Ø 1.9 mm.

| Technical data | |
|--------------------------------------|---|
| Diameter of plug system | 2 mm |
| Rated Values | 1000 V, CAT II, 10 A / 600 V, CAT III, 10 A |
| Surface treatment electrical contact | Au |
| Base material electrical contact | CuZn |
| Standard color(s) * | 21 22 23 24 25 29 |
| Test accessory acc. to | IEC EN 61010-2-030 |
| Supplied assembly material | MUR/M8x0,5; SP4 |
| Remarks | Accessories: Flat connecting receptacle FSH2,8x0,8; Tube spanner SS4; Tube spanner SS2-S |
| Approvals | UR |