


XSMF-419

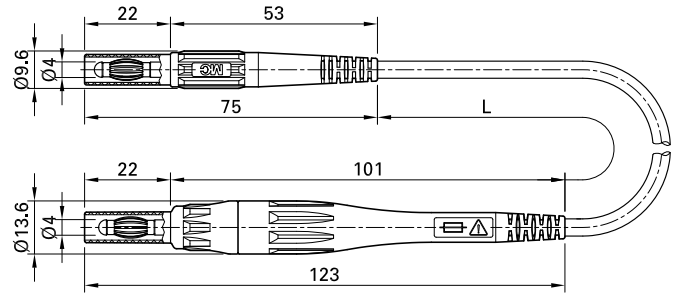

Item number 66.9394-*

Highly flexible, with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve on both ends. Test lead with integrated high breaking capacity fuses designed for 1000 V, CAT IV in accordance with IEC/EN 61010-031 and allow for the use of Ø 4 mm safety probes and test clips for fuse-protected

d measurements. The two-part fused connector can be easily unscrewed and accepts a high breaking capacity fuse measuring 6.3 x 32 mm. The fuse is not supplied.

Technical data	
Diameter of plug system	4 mm
Rated Values	1000 V, CAT IV, 8 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	<input type="checkbox"/> 21 <input type="checkbox"/> 22 <input type="checkbox"/> 23 <input type="checkbox"/> 24 <input type="checkbox"/> 25 <input type="checkbox"/> 26 <input type="checkbox"/> 27 <input type="checkbox"/> 28
Optional color(s)	<input type="checkbox"/> 29
Lead lengths <input type="text"/>	100; 150; 200 cm
Lead insulation	PVC
Lead cross section	1,0 mm ²
Test accessory acc. to	IEC EN 61010-031
User-Information	I 091
Remarks	Accessories: High breaking capacity fuse DMI-0,5A; High breaking capacity fuse DMI-1,6 A
Approvals	UL, CE