
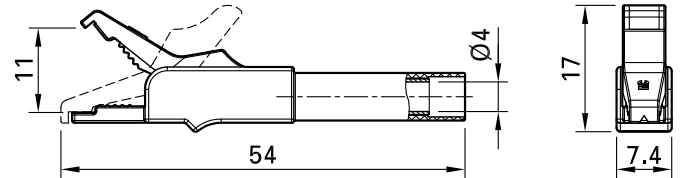


SAGK4-K

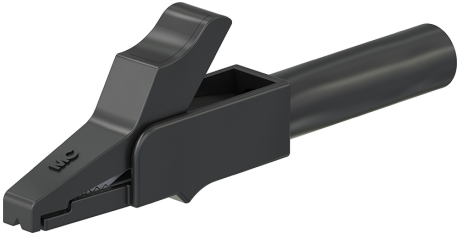

Item number 24.0157-*

Small, slim, made of brass with all-round insulation. Toothed jaws for wide grip with surface for fine wire. Ø 4 mm rigid socket in insulator accepting spring-loaded Ø 4 mm plugs with rigid insulating sleeve.

Technical data	
Diameter of plug system	4 mm
Rated Values	300 V, CAT II, 15 A
Surface treatment electrical contact	Ni
Base material electrical contact	CuZn
Standard color(s) *	21 22 23
Opening width	11.0 mm
Test accessory acc. to	IEC EN 61010-031
Approvals	CE