


XHL-5000

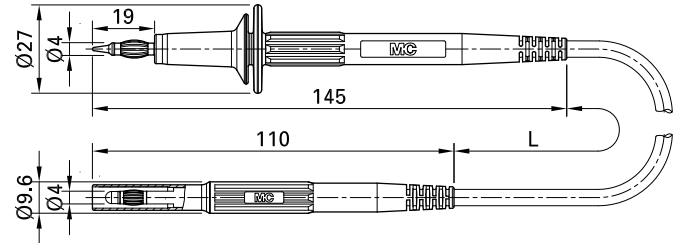

Item number 66.9426-*

Highly flexible, one end with Ø 4 mm test probe with spring-loaded MULTILAM, the other end with in-line Ø 4 mm MULTILAM plug with rigid insulating sleeve. Supplied with protective cap.

| Technical data | |
|--------------------------------------|---|
| Diameter of plug system | 4 mm |
| Rated Values | 1000 V, CAT IV, 10 A |
| Surface treatment electrical contact | Ni |
| Base material electrical contact | CuZn |
| Standard color(s) * | 21 22 23 |
| Lead lengths <input type="text"/> | 150 cm |
| Lead insulation | TPE |
| Lead cross section | 0,5 mm ² |
| Test accessory acc. to | IEC EN 61010-031 |
| User-Information | I 109 |
| Remarks | Rated voltage 5'000 V: Output voltage of test instruments, e.g. insulation testers |
| Approvals | CE |