


ROLINE USB 3.2 Gen 1 Hub, 4 Ports, Type C Connection Cable

| | |
|---------------------------|---------------|
| Product No. | 14.02.5053 |
| Manufacturer | ROLINE |
| Manufacturer No. | 14.02.5053 |
| EAN (single piece) | 7630049626393 |

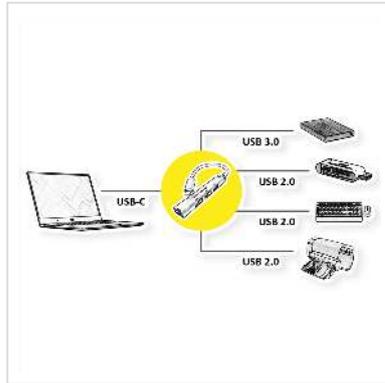

4-Port USB 3.2 Gen 1 Slim Hub made of dark grey aluminium with USB Type C connection cable - for connecting up to four peripheral or storage devices to a tablet (like an Apple iPad Pro), Ultrabook, Notebook/Laptop or PC via USB Type C.

- 4-port USB 3.2 Gen 1 Type A hub with data rates of up to 5Gbit/s
- Suitable for Tablets, Macs/MacBooks, Ultrabooks, Notebooks/Laptops or PCs via USB Type C
- Suitable for peripherals such as keyboard, mouse and printer or for mass storage devices such as USB sticks and external hard drives
- Slim Hub with extremely small and slim housing
- Dark grey aluminium housing
- Power supply via USB Type C

Note: According to the current specifications of USB.org we have adapted the technical data of our USB 3 products. The new designation for the already known USB specifications has been changed to USB 3.2 Gen 1 (formerly USB 3.0 / USB 3.1 Gen 1) and USB 3.2 Gen 2 (formerly USB 3.1 / USB 3.1 Gen 2).

Technical specifications

| | |
|---------------|-----------|
| Manufacturer | ROLINE |
| Product group | Hubs |
| Product type | USB Hub |
| Colour | Aluminium |
| Length | 0.1 m |

| | |
|------------------------------------|--|
| Scope of delivery | Hub |
| PC connection | 1x USB Type C |
| Device connection | 4x USB Type A |
| Transfer quality | USB 3.2 Gen 1 SuperSpeed 5 Gbit/s (USB 3.1 Gen 1, USB 3.0) |
| Side 1 Connector Type | USB Type C (USB-C) |
| Side 1 Connector Gender | Male |
| Side 2 Connector Type | USB 3 Type A |
| Side 2 Connector Gender | Female |
| Quantity of ports | 4 |
| Area of application | External |
| Material (casing) | Aluminium |
| Dimensions (HxWxD) | 7 x 105 x 18 mm |
| Power supply unit required | No |
| Height | 7 mm |
| Width | 105 mm |
| Depth | 18 mm |
| Weight | 26 g |
| Height of packaging (single piece) | 50 mm |
| Width of packaging (single piece) | 10 mm |
| Depth of packaging (single piece) | 100 mm |
| Package weight (single piece) | 0.02 kg |