

# PC 300/150 ZT



Sample image

**Order symbol :** PC 300/150 ZT

**Product nr :** 6017938

**Description :** Enclosure, PC




**Remarks :** Smoked transparent cover

**EAN :** 6418074061522

**El. number :**

- Finland : 3435626
- Denmark : 8212027996
- Sweden : 6017938

**Including :** Base with TPE gasket. screws for mounting plate/DIN-rail and cover with polyamide cover screws.

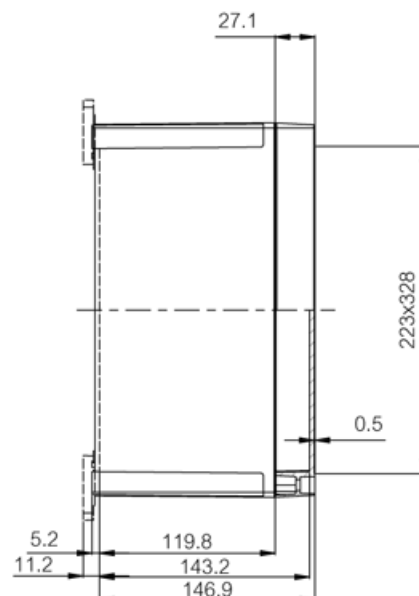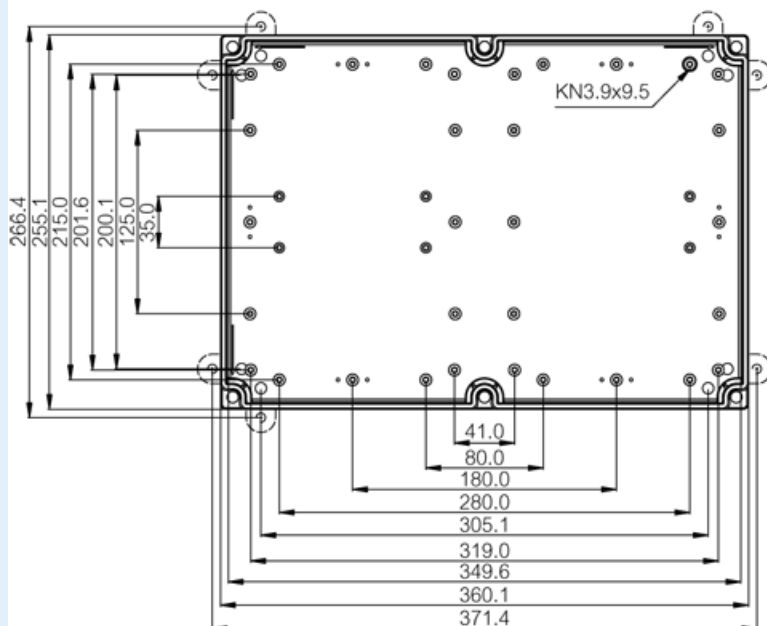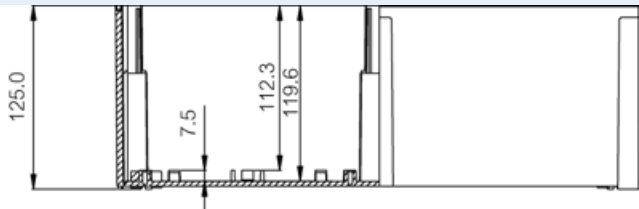

| Dimensions : | Height | Width | Depth |
|--------------|--------|-------|-------|
| mm :         | 360    | 255   | 152   |
| inch :       | 14.17  | 10.04 | 5.98  |

| Materials :       |                      |
|-------------------|----------------------|
| Material :        | Polycarbonate        |
| Base colour :     | RAL 7035 -light grey |
| Cover colour :    | Clear transparent    |
| Gasket material : | Polyurethane         |

| Temperatures :                |             |
|-------------------------------|-------------|
| Temperature °C (short term) : | -40 ... 120 |
| Temperature °C (continuous) : | -40 ... 80  |
| Temperature °F (short term) : | -40 ... 250 |
| Temperature °F (continuous) : | -40 ... 175 |

| Accessories : |                                                                       |
|---------------|-----------------------------------------------------------------------|
| MIN 20        | DIN-15 Mounting rail, for enclosures:<br>(225 x 15 x 1)               |
| MIV 150       | Mounting plate (Galvanized steel), for enclosures:<br>(148 x 98 x 1)  |
| MIN 15        | DIN-15 Mounting rail, for enclosures:<br>(150 x 15 x 1)               |
| MIV 200       | Mounting plate (Galvanized steel), for enclosures:<br>(223 x 148 x 1) |
| MIV 30        | DIN-35 Mounting rail, for enclosures:<br>(329 x 35 x 1)               |
| MIV 15        | DIN-35 Mounting rail, for enclosures:<br>(150 x 35 x 1)               |
| FP 10674      | Wall fastening lug (2 pcs) incl. screws                               |
| MIV 300       | Mounting plate (Galvanized steel), for enclosures:<br>(330 x 225 x 0) |
| MIV 20        | DIN-35 Mounting rail, for enclosures:<br>(225 x 35 x 1)               |

| Ratings :                               |                   |
|-----------------------------------------|-------------------|
| Ingress protection (EN 60529):          | IP66; IP67;       |
| Impact Resistance (EN 62262):           | IK08;             |
| electrical_insulation :                 | Totally insulated |
| Halogen free (DIN/VDE 0472, Part 815) : | Yes               |
| UV resistance :                         | UL 508            |
| Flammability Rating :                   | UL 94 V0          |
| Glow Wire Test (IEC 695-2-1) °C :       | 960 °C            |

| Certificates :       |  |
|----------------------|--|
| Certificate FI 40847 |  |