


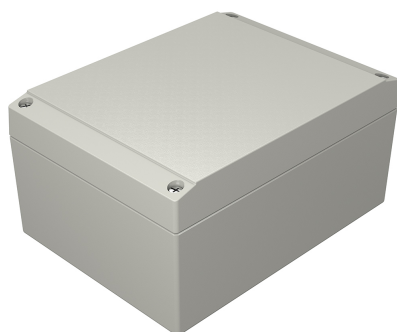

04121608

Aluminium Enclosure Aluform

120 x 160 x 81 mm

Aluminium Enclosure Aluform 120 x 160 x 81 mm

[Catalogues](#)[Assembly instructions](#)[Declaration of Conformity](#)[Drawing](#)[3D Data](#)[Assignmentplan](#)[Terminal Mounting](#)

Technical data

Height	120 mm
Width	160 mm
Depth	81 mm
Material	Aluminium
Material quality	DIN EN 1706 EN AC-AISI 12 (Fe)
Colour	Agate grey (RAL 7038)
Ingress protection	IP66
Degree of protection norm	EN 60529
Impact strength	IK09
temperature min.	-60 °C
temperature max.	130 °C
Seal material	PU (polyurethane) (standard)
Flame spread, sideways	HL 3
Rate of head dispersion	HL 3
Other versions on request	EMV, SBG, SWB, SBGL
Special colours on request	Yes
Approvals	Lloyd Register, Maritime Register, UL 508A

Commercial data

Country of origin	IN
Order unit	1 Piece
Customs tariff number	85369095
Weight	0.83 kg
GTIN	4250157901132

ETIM classification

ETIM 8	EC000058
--------	----------

ROSE SYSTEMTECHNIK GMBH
Erbeweg 13-15
32457 Porta Westfalica, Germany

Tel.: +49 571 50 41-0
Fax: +49 571 50 41-6
Mail: rose@rose-pw.de

Accessories

	04000010 Aluform External hinges		04000020 Aluform Lid safety strip
	04000120 Aluform External mounting bracket 120		10011063 Mounting plate for 04.121608
	10061008 DIN rail 15 for 01.101608		10061472 DIN rail 35/7,5 for 04.101606