



### Type label identification, laser printer

#### Helatag 1101 (White)


Used where clarity of print is most important and is ideally suited for printing barcodes and high definition graphics.

A range of sizes and materials are available to suit most cable marking and asset identification needs.

For problem-free printing, we recommend our easy to use windows based TagPrint Pro software program, which comes pre-loaded with all our standard label templates so you can start producing labels immediately.

#### Features and benefits

- White rating labels for component marking as well as for control cabinets
- For use on flat and smooth surfaces
- Crisp and clear text, barcodes and graphics
- Simple and efficient label design and printing with TagPrint Pro labelling software
- Templates available from [www.HellermannTyton.com](http://www.HellermannTyton.com) for those wishing to use MS Word
- Clear protective box to ensure labels stay as good as new

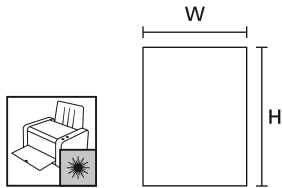

Helatag label for permanent asset identification.

<b>MATERIAL</b>	Type 1101, Polyester, white (1101)
<b>Operating Temperature</b>	-40 °C to +150 °C
<b>Curing Temperature</b>	from 0 °C
<b>Adhesive</b>	Acrylic
<b>Thickness of Foil</b>	55 µm
<b>Chem. Material Properties</b>	Excellent resistance against water, alcohol, most oils, lubricants, fuels, aliphatic solvents, weak acid, salts, alkalis and UV light.



TYPE	Width (W)	Height (H)	Labels per Sheet	Sheets per Pack	Pack Cont.	Colour	Article-No.
TAG156LA4-1101-WH	10.2	10.2	532 pcs.	19 pcs.	10,000 pcs.	White (WH)	594-81101
TAG122LA4-1101-WH	15.0	9.0	372 pcs.	27 pcs.	10,000 pcs.	White (WH)	594-31101
TAG120LA4-1101-WH	15.2	6.4	528 pcs.	19 pcs.	10,000 pcs.	White (WH)	594-11101
TAG111LA4-1101-WH	16.5	5.1	605 pcs.	17 pcs.	10,000 pcs.	White (WH)	594-01101
TAG154LA4-1101-WH	17.0	9.0	341 pcs.	30 pcs.	10,000 pcs.	White (WH)	594-61101
TAG124LA4-1101-WH	19.0	11.0	260 pcs.	20 pcs.	5,000 pcs.	White (WH)	594-11017
TAG131LA4-1101-WH	19.1	6.4	440 pcs.	23 pcs.	10,000 pcs.	White (WH)	594-41101
TAG121LA4-1101-WH	20.0	8.0	315 pcs.	32 pcs.	10,000 pcs.	White (WH)	594-21101
TAG155LA4-1101-WH	25.4	8.5	231 pcs.	22 pcs.	5,000 pcs.	White (WH)	594-71101
TAG151LA4-1101-WH	25.4	12.7	154 pcs.	33 pcs.	5,000 pcs.	White (WH)	594-91101
TAG62LA4-1101-WH	31.8	9.5	180 pcs.	28 pcs.	5,000 pcs.	White (WH)	594-11016
TAG162LA4-1101-WH	38.1	12.7	110 pcs.	23 pcs.	2,500 pcs.	White (WH)	594-11010
TAG150LA4-1101-WH	48.3	8.5	132 pcs.	19 pcs.	2,500 pcs.	White (WH)	594-51101
TAG163LA4-1101-WH	48.3	12.7	88 pcs.	29 pcs.	2,500 pcs.	White (WH)	594-11011
TAG165LA4-1101-WH	48.3	21.2	52 pcs.	20 pcs.	1,000 pcs.	White (WH)	594-11012
TAG169LA4-1101-WH	48.3	33.9	32 pcs.	32 pcs.	1,000 pcs.	White (WH)	594-11013
TAG170LA4-1101-WH	63.5	33.9	24 pcs.	21 pcs.	500 pcs.	White (WH)	594-11014
TAG171LA4-1101-WH	210.0	297.0	1 pc.	25 pcs.	25 pcs.	White (WH)	594-11015

All dimensions in mm. Subject to technical changes.  
Minimum Order Quantity (MOQ) may differ from package content. Other packaging options may also be available.



For product specific approvals and specifications please refer to the Appendix.

