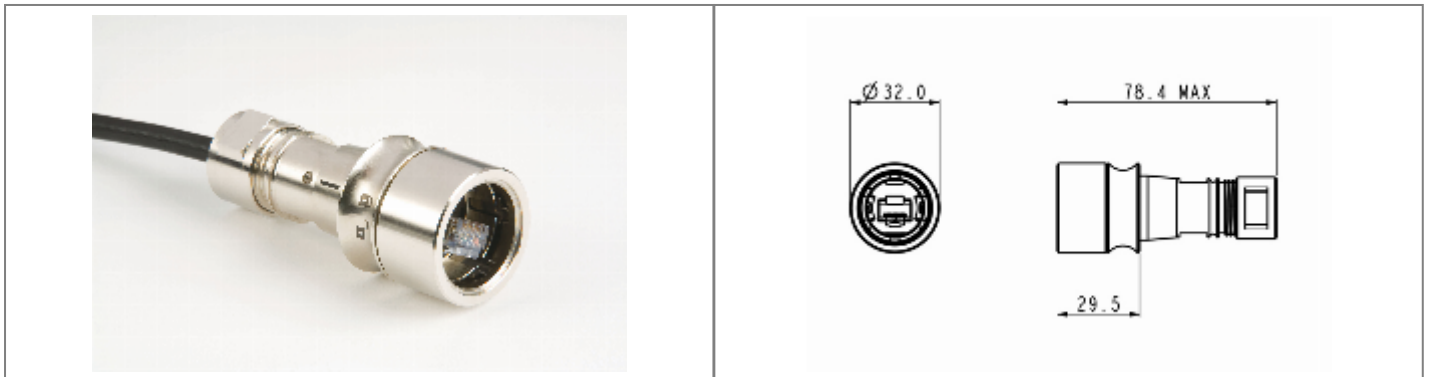


PXM6034/A Datasheet

Product Name // Rewireable Flex Connector PXM6034 Series PUR CAT5e Cable Metal Body

[View Product Page](#)


// Product Description:

- ⊕ Rewireable Flex Cable Connectors
- ⊕ Water and dustproof to IP66, IP68, IP69K when mated with compatible connector
- ⊕ 30 degree push twist locking, tamperproof lock prevents accidental un-mating
- ⊕ Supplied with shielded RJ45 plug
- ⊕ Choice of cable acceptance depending on part code:
- ⊕ Part codes suffixed /A have cable glands optimised for PUR jacket cable to maintain CAT5e performance
- ⊕ Part codes suffixed /B accept cable 4mm-10mm diameter
- ⊕ Choice of body material depending on part code:
- ⊕ Plastic body (part codes prefixed PXP)
- ⊕ Metal body (part codes prefixed PXM)
- ⊕ PXP6081/PXM6081 Sealing Cap available separately to maintain IP rating of unmated connectors
- ⊕ Mate with PXP6033TP, PXP6033TP/E, PXM6033TP Front Panel Mount CAT5e Couplers

// General Information:

Product Display Title:	Rewireable Flex Cable Connectors
Product Family:	Circular Data Connectors
Product Series:	6000 Series - Ethernet Buccaneer
Body Material:	Brass - Nickel Plated
Body Material Type:	Metal Body
Contact Type:	Plug Contact
Coupling Type:	Push-Twist
Current Max:	1.5A
Diameter Over Coupling Ring Mm:	32mm
Ethernet Category:	Cat 5e
Function:	Flex Cable Connector
Ip Rating:	IP66, IP68, IP69K
Max Cable Entry Size:	7mm
Min Cable Entry Size:	5mm
Max Operating Temperature:	+70°C
Min Operating Temperature:	-20°C
Number Of Contacts:	8 Contacts
Voltage Max:	42V

// Product PDF Links

[6000 Series Ethernet connectors...](#)
[6000 Series Ethernet connectors...](#)

// Product 3D CAD Model Links

[PXM6034/A3D CAD Model](#)