


# PX0841/AB/3M00 Datasheet

**Product Name // Overmoulded USB Cable PX0841 Series  
USB Sealed A Plug to Sealed B Plug 3M Cable**

[View Product Page](#)

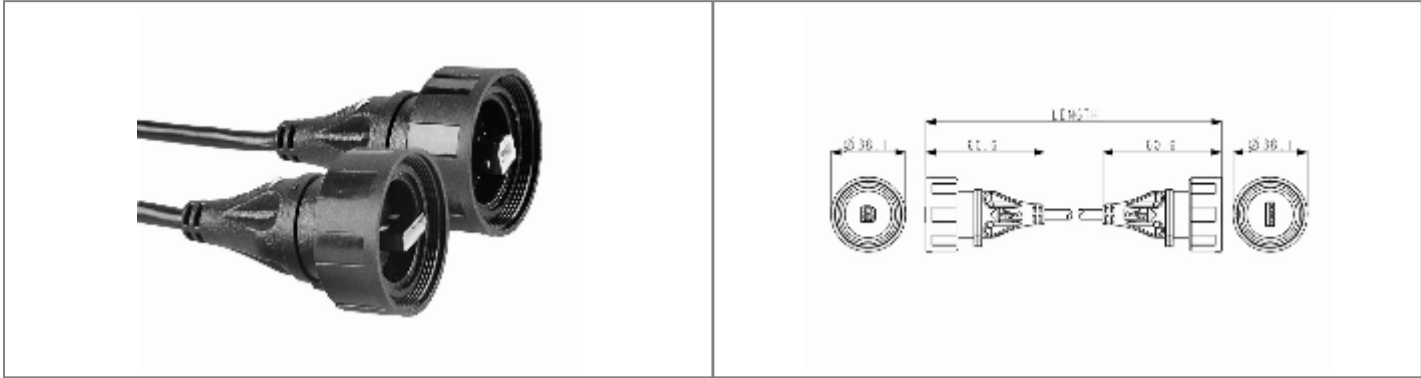

## // Product Description:

- ⊕ Pre-Wired Overmoulded USB V2.0 Cable
- ⊕ Water and dustproof to IP68 when mated with compatible connector
- ⊕ Sealed Standard USB Type A plug to Sealed Standard USB Type B plug
- ⊕ Choice of cable lengths depending on part code suffix
- ⊕ PX0835 Sealing Cap available separately to maintain IP rating of unmated connectors
- ⊕ Mate with PX08 Standard USB Series Panel Mount Connectors

## // General Information:

<p><b>Product Display Title:</b></p> <p><b>Product Family:</b></p> <p><b>Product Series:</b></p> <p><b>Approvals:</b></p> <p><b>Body Material:</b></p> <p><b>Contact Type:</b></p> <p><b>Coupling Type:</b></p> <p><b>Current Max:</b></p> <p><b>Data Cable Type:</b></p> <p><b>Diameter Over Coupling Ring Mm:</b></p> <p><b>Flamability Rating:</b></p> <p><b>Function:</b></p> <p><b>Ip Rating:</b></p> <p><b>Max Operating Temperature:</b></p> <p><b>Min Operating Temperature:</b></p> <p><b>Number Of Contacts:</b></p> <p><b>Voltage Max:</b></p>	<p>Pre-Wired Overmoulded USB V2.0 Cable</p> <p>Circular Data Connectors</p> <p>Standard Buccaneer - USB</p> <p>CSA, UL, VDE</p> <p>PVC</p> <p>Plug Contact</p> <p>Screw</p> <p>1A</p> <p>USB Sealed A Plug to Sealed B Plug</p> <p>38.1mm</p> <p>UL94V-0</p> <p>Flex to Flex Connector Double Ended Cable</p> <p>IP68, IP69K</p> <p>+70°C</p> <p>0°C</p> <p>4 Contacts</p> <p>30V</p>
---	---

**// Product PDF Links**

[Standard Series USB connectors...](#)