


PX2001S04BK Datasheet

Product Name // 4 Contacts Female Automotive
Rectangular Black Connector

 [View Product Page](#)

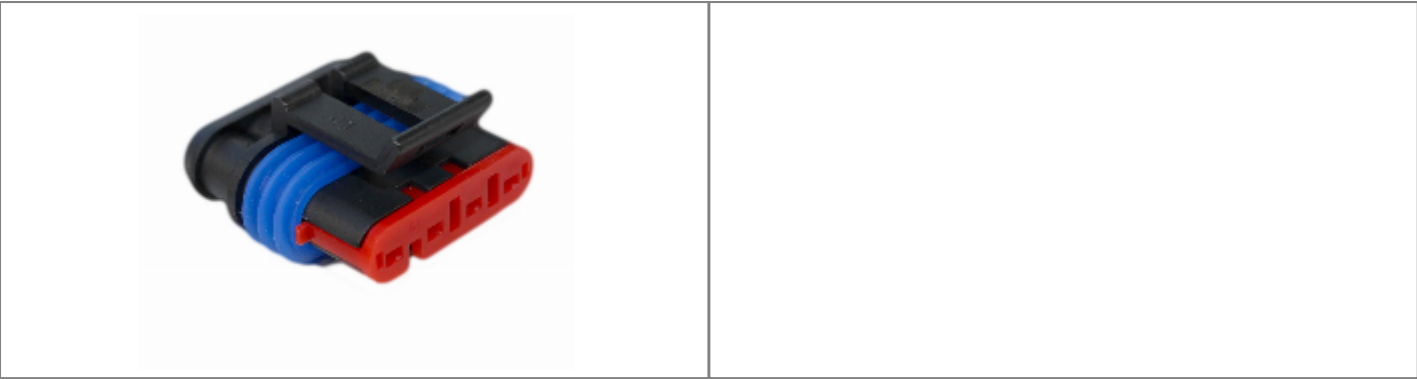

// Product Description:



4 Contacts Female Automotive Rectangular Black Connector



IP67 rated when mated



Mate with PX2000 Series



Wedge locks provided



Crimp Terminals



Mechanical Cycles=100 (min)



Operating Temperature= -40Â°C to +125Â°C

// General Information:

Product Display Title:

Product Family:

Product Series:

Body Colour:

Body Material:

Body Material Type:

Contact Type:

Coupling Type:

Current Max:

Dielectric Withstanding Voltage:

Durability:

Function:

Insulation Resistance:

Ip Rating:

Max Operating Temperature:

Min Operating Temperature:

Number Of Contacts:

Rohs Compliant:

Voltage Max:

4 Contacts Female Automotive Rectangular Black Connector

Rectangular Connectors

Automotive Rectangular Connectors

Black

Polybutylene Terephthalate (PBT)

Plastic Body

Plug Contact

Snap-in

14A

1500V

>100 Cycles

Straight Female Connector

>2000MOhms

IP67

+125°C

-55°C

4 Contacts

Yes

24V

// Product PDF Links

 Rectangular Power Connector...