


PX2001S03BK Datasheet

Product Name // 3 Contacts Female Automotive Rectangular Black Connector

[View Product Page](#)

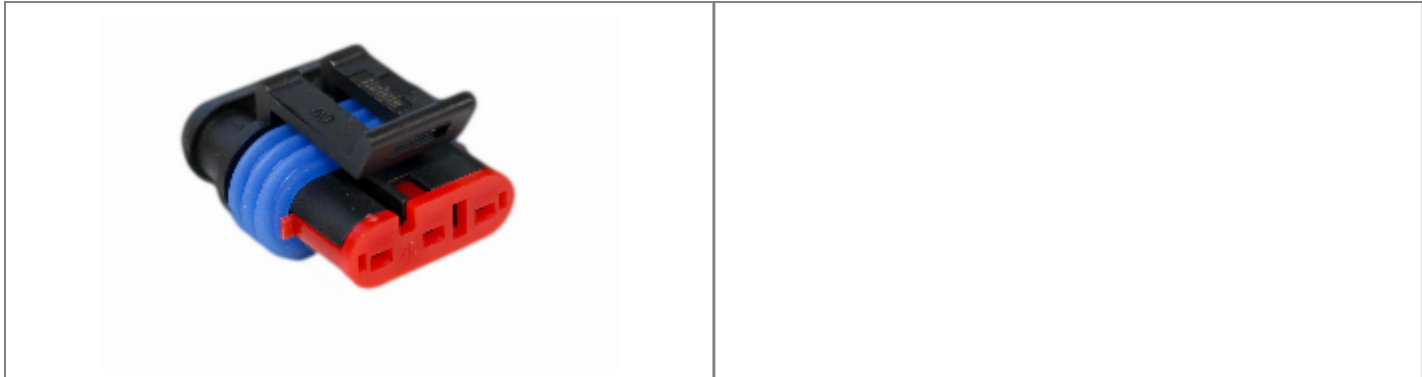

// Product Description:

- ⊕ 3 Contacts Female Automotive Rectangular Black Connector
- ⊕ IP67 rated when mated
- ⊕ Mate with PX2000 Series
- ⊕ Wedge locks provided
- ⊕ Crimp Terminals
- ⊕ Mechanical Cycles=100 (min)
- ⊕ Operating Temperature= -40Å°C to +125Å°C

// General Information:

Product Display Title:	3 Contacts Female Automotive Rectangular Black Connector
Product Family:	Rectangular Connectors
Product Series:	Automotive Rectangular Connectors
Body Colour:	Black
Body Material:	Polybutylene Terephthalate (PBT)
Body Material Type:	Plastic Body
Contact Type:	Plug Contact
Coupling Type:	Snap-in
Current Max:	14A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Female Connector
Insulation Resistance:	>2000MOhms
Ip Rating:	IP67
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	3 Contacts
Rohs Compliant:	Yes
Voltage Max:	24V

// Product PDF Links

[Rectangular Power Connector...](#)