


PX2000P04BK Datasheet

Product Name // 4 Contacts Male Automotive Rectangular Black Connector

[View Product Page](#)

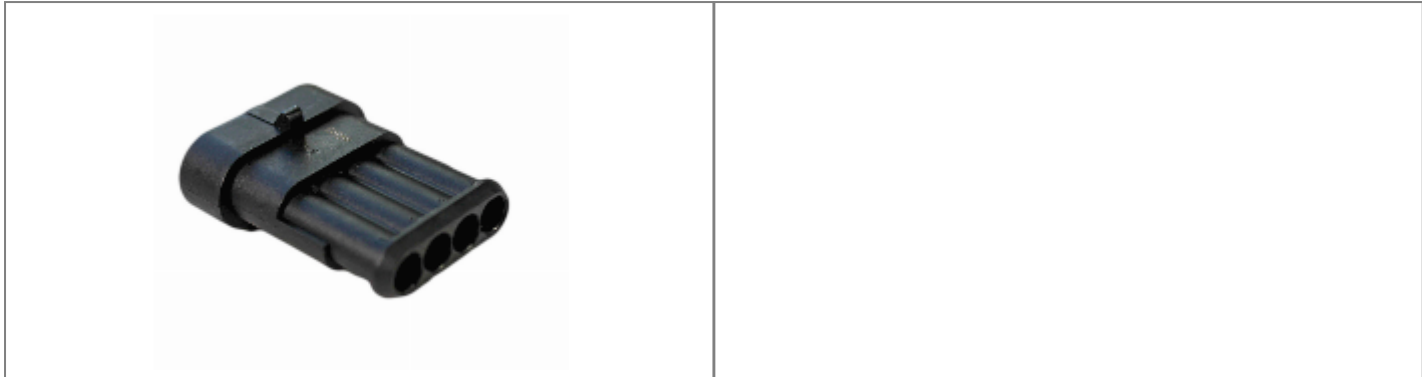


// Product Description:

- ⬡ 4 Contacts Male Automotive Rectangular Black Connector
- ⬡ IP67 rated when mated
- ⬡ Mate with PX2001 Series
- ⬡ Wedge locks provided
- ⬡ Crimp Terminals
- ⬡ Mechanical Cycles=100 (min)
- ⬡ Operating Temperature= -40Å°C to +125Å°C

// General Information:

Product Display Title:	4 Contacts Male Automotive Rectangular Black Connector
Product Family:	Rectangular Connectors
Product Series:	Automotive Rectangular Connectors
Body Colour:	Black
Body Material:	Polybutylene Terephthalate (PBT)
Body Material Type:	Plastic Body
Contact Type:	Socket Contact
Coupling Type:	Snap-in
Current Max:	14A
Dielectric Withstanding Voltage:	1500V
Durability:	>100 Cycles
Function:	Straight Male Connector
Insulation Resistance:	>2000MOhms
Ip Rating:	IP67
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Number Of Contacts:	4 Contacts
Rohs Compliant:	Yes
Voltage Max:	24V

// Product PDF Links

 [Rectangular Power Connector...](#)