





# SA1025 Datasheet

**Product Name // Tin Plated 15-18 AWG Stamped Socket Contact - Bandolier**

[View Product Page](#)

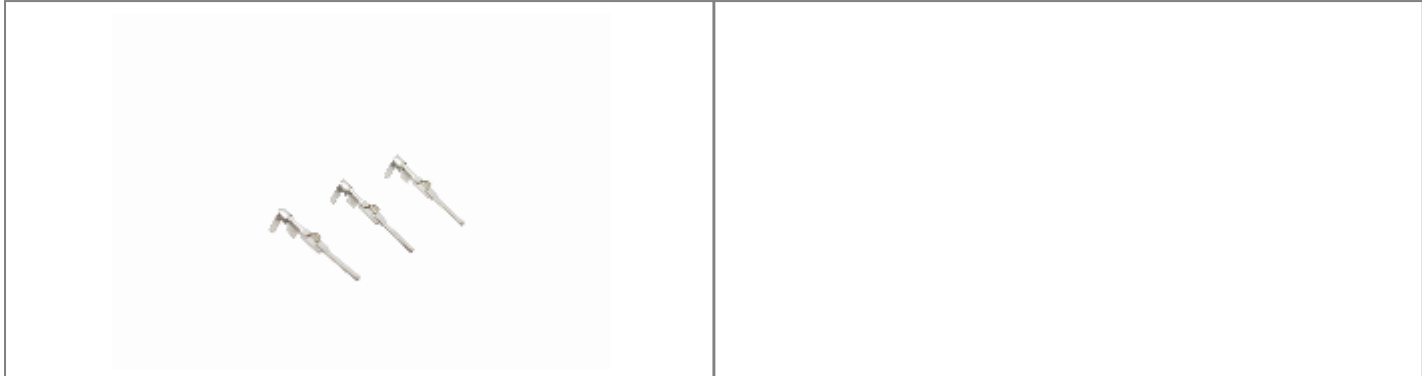


**// Product Description:**


-  Tin Plated 15-18 AWG Stamped Socket Contact - Bandolier
-  Crimp Terminals
-  Operating Temperature= -55°C to +125°C

**// General Information:**

Product Display Title:	Tin Plated 15-18 AWG Stamped Socket Contact - Bandolier
Product Family:	Rectangular Connectors
Product Series:	Automotive Rectangular Connectors- Contact - Bandoliers
Body Material:	Cooper Alloy
Contact Type:	Socket Contact - Bandolier Contact - Bandolier
Function:	Crimp Contact - Bandolier
Material Finish:	Tin Plated Plated
Max Contact Accomodation Awg:	18AWG
Min Contact Accomodation Awg:	15AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes

**// Product PDF Links**

 [Rectangular Power Connector...](#)

 Have a question or project enquiry you'd like to talk to us about?

 [Click Here To Contact Us](#)