


# SA1018 Datasheet

**Product Name // Nickel Plated 12-14 AWG Stamped Plug Contact - Bandolier**

[View Product Page](#)

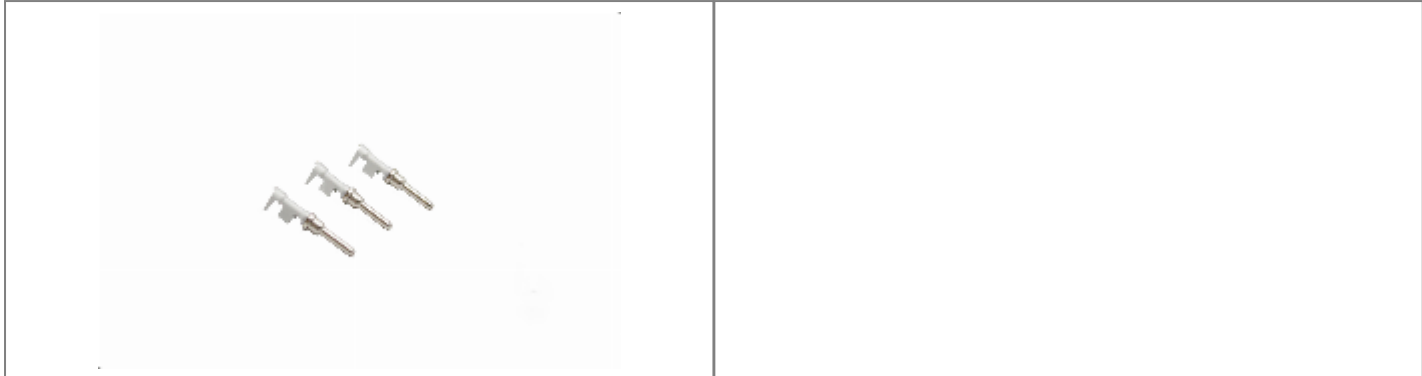

**// Product Description:**


- ⬡ Nickel Plated 12-14 AWG Stamped Plug Contact - Bandolier
- ⬡ Crimp Terminals
- ⬡ Operating Temperature= -55Â°C to +125Â°C

**// General Information:**

Product Display Title:	Nickel Plated 12-14 AWG Stamped Plug Contact - Bandolier
Product Family:	Rectangular Connectors
Product Series:	Power Rectangular Connectors- Contact - Bandoliers
Body Material:	Cooper Alloy
Contact Type:	Plug Contact - Bandolier Contact - Bandolier
Function:	Crimp Contact - Bandolier
Material Finish:	Nickel Plated Platin-platedg
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	12AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes

**// Product PDF Links**

[Rectangular Power Connector...](#)

 Have a question or project enquiry you'd like to talk to us about?

[Click Here To Contact Us](#)