


PX0103S02GY Datasheet

Product Name // 2 Contacts Male Standard Rectangular Grey Connector - ESR & PEC

[View Product Page](#)

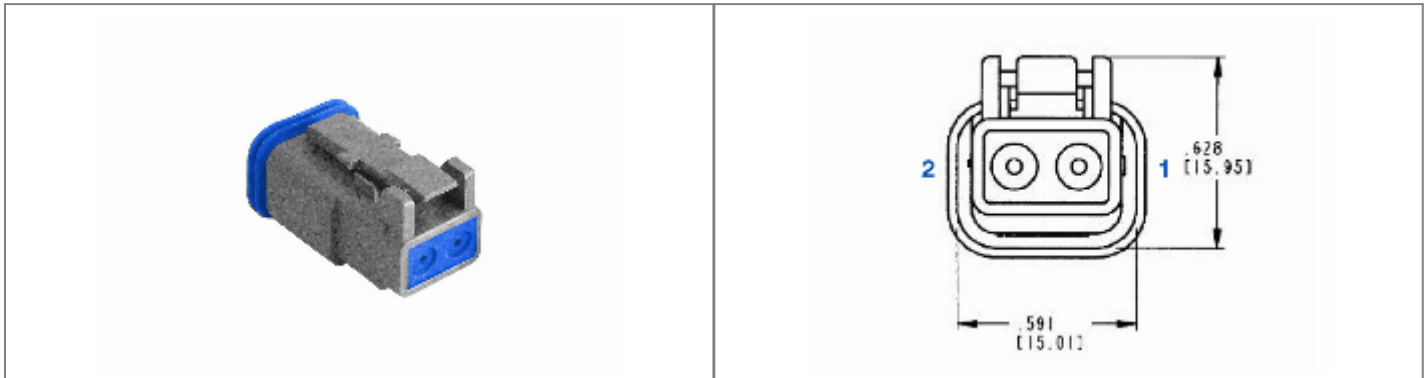

// Product Description:

- ⬢ 2 Contacts Male Standard Rectangular Grey Connector - ESR & PEC
- ⬢ Enhanced Seal Protection (ESR) and Protective End Cap (PEC) Included
- ⬢ IP68 rated when mated
- ⬢ Mate with PX0101 Series
- ⬢ Wedgelocks provided
- ⬢ Crimp Terminals
- ⬢ Mechanical Cycles=100 (min)
- ⬢ Operating Temperature= -55Å°C to +125Å°C

// General Information:

<p>Product Display Title:</p> <p>Product Family:</p> <p>Product Series:</p> <p>Body Colour:</p> <p>Body Material:</p> <p>Body Material Type:</p> <p>Contact Type:</p> <p>Coupling Type:</p> <p>Current Max:</p> <p>Dielectric Withstanding Voltage:</p> <p>Durability:</p> <p>Function:</p> <p>Insulation Resistance:</p> <p>Ip Rating:</p> <p>Max Contact Accomodation Awg:</p> <p>Min Contact Accomodation Awg:</p> <p>Max Operating Temperature:</p> <p>Min Operating Temperature:</p> <p>Number Of Contacts:</p> <p>Rohs Compliant:</p> <p>Voltage Max:</p>	<p>2 Contacts Male Standard Rectangular Grey Connector - ESR & PEC</p> <p>Rectangular Connectors</p> <p>Standard Rectangular Connectors</p> <p>Grey</p> <p>Polycarbonate/Polybutylene Terephthalate (PC/PBT)</p> <p>Plastic Body</p> <p>Socket Contact</p> <p>Snap-in</p> <p>13A</p> <p>1500V</p> <p>>100 Cycles</p> <p>Straight Male Connector</p> <p>>1000MOhms</p> <p>IP68</p> <p>20AWG</p> <p>14AWG</p> <p>+125°C</p> <p>-55°C</p> <p>2 Contacts</p> <p>Yes</p> <p>250V</p>
--	---

// Product PDF Links

[Rectangular Power Connector...](#)

Have a question or project enquiry you'd like to talk to us about?

[Click Here To Contact Us](#)