


SA1010/G Datasheet

Product Name // Gold Plated 14 AWG Solid Socket Contact - Green Stripe

[View Product Page](#)

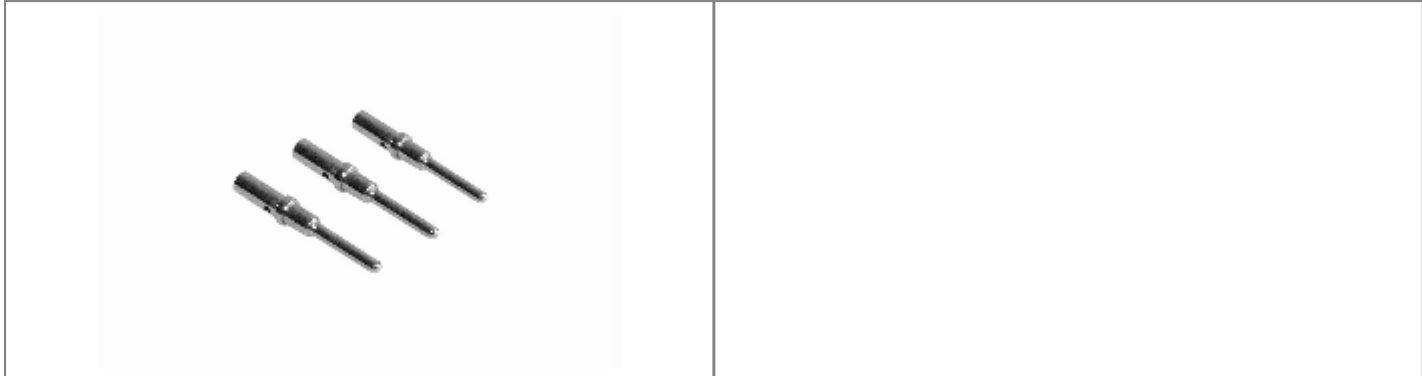

// Product Description:


- ⬢ Gold Plated 14 AWG Solid Socket Contact - Green Stripe
- ⬢ Crimp Terminals
- ⬢ Operating Temperature= -55Â°C to +125Â°C

// General Information:

Product Display Title:	Gold Plated 14 AWG Solid Socket Contact - Green Stripe
Product Family:	Rectangular Connectors
Product Series:	Standard Rectangular Connectors- Contacts
Body Material:	Cooper Alloy
Contact Type:	Socket Contact
Function:	Crimp Contact
Material Finish:	Gold Plated Platin-platedg
Max Contact Accomodation Awg:	14AWG
Min Contact Accomodation Awg:	14AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes

// Product PDF Links

[Rectangular Power Connector...](#)

 Have a question or project enquiry you'd like to talk to us about?

[Click Here To Contact Us](#)