


SA1015 Datasheet

Product Name // Nickel Plated 16-22 AWG Stamped
Socket Contact - Bandolier

 [View Product Page](#)

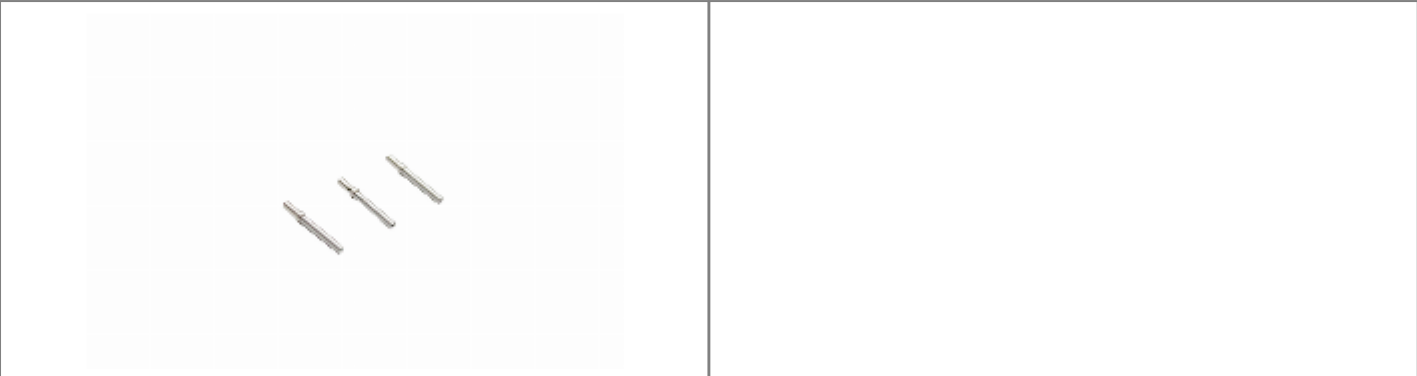

// Product Description:

-  Nickel Plated 16-22 AWG Stamped Socket Contact - Bandolier
-  Operating Temperature= -55Â°C to +125Â°C
-  Crimp Terminals

// General Information:

Product Display Title:	Nickel Plated 16-22 AWG Stamped Socket Contact - Bandolier
Product Family:	Rectangular Connectors
Product Series:	Minituare Rectangular Connectors- Contact - Bandoliers
Body Material:	Cooper Alloy
Contact Type:	Socket Contact - Bandolier Contact - Bandolier
Function:	Crimp Contact - Bandolier
Material Finish:	Nickel Plated Platin-platedg
Max Contact Accomodation Awg:	22AWG
Min Contact Accomodation Awg:	16AWG
Max Operating Temperature:	+125°C
Min Operating Temperature:	-55°C
Rohs Compliant:	Yes

// Product PDF Links

 Rectangular Power Connector...