

HellermannTyton

DATA SHEET

Nylon Glands


Description

Nylon domed headed cable glands are quick and easy to install and cater for a wide range of cable sizes. A range of quality nylon cable glands that can be used on a wide range of applications when connecting cable to electrical equipment (but not steel wire armored cable)

Application

Nylon cable glands that can be used on a wide range of applications when connecting cable to electrical equipment (but not steel wire armored cable).

Properties


Properties	Typical Results
Material	Nylon PA6 or PA66
Continuous Operating Temp	-40°C~100°C
Short Time Temperature	+120°C
Flame Rating	UL94 V2 (V0 is optional)
IP Rating	IP68
Standards	
Colours	Black, Grey, Light Grey and Red (Standard) other colours are available upon request



HellermannTyton

DATA SHEET

Nylon Glands

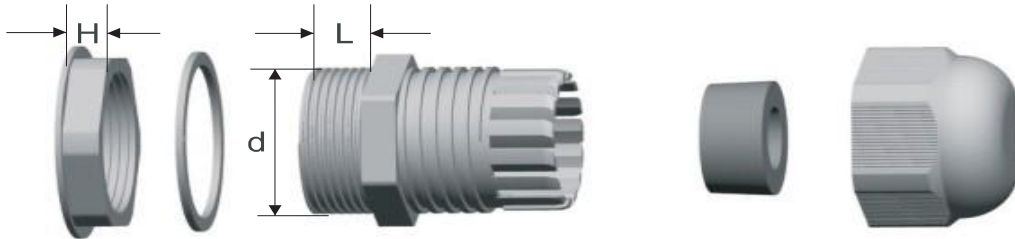

HT Part Number	Cable Range mm	d mm	Spanner Size		H mm	L mm	Pack Quantities
			Body mm	Lock Nut mm			
NGM12	3-6.5	12	15	19	5.0	8.0	10
NGM16	5-10	16	21	22	5.0	15.0	10
NGM20S	7-12	20	24	27	6.0	9.0	10
NGM20	10-14	20	24	27	6.0	15.0	10
NGM25	13-18	25	32	32	6.0	15.0	10
NGM32	16-21	32	37	42	7.0	14.0	5
NGM40	20-26	40	50	51	7.0	18.0	5
NGM50	30-38	50	56	59	10.5	18.5	2
NGM63	37-44	63	68	75	11.3	20.4	2