

RF Product Information

■RFDPA131000SMRB801 Series for UHF Application at 863~928 MHz

Application

- UHF 863~928 MHz in smart meter, industrial data acquisition system and door control system
- Device for external UHF system

Recommended Link Parts

RFCON161202SF6B001(On Board RF Connector)

RFCBA100608SF6B310(Connected To Module's Coaxial Cable)



ELECTRICAL CHARACTERISTICS


Item	Specification
Frequency Range	863~928 MHz
Impedance	50 Ohm Nominal
VSWR	2.5 Max.
Radiation	Omni-directional
Polarization	Linear Vertical
Admotted Power	1W


MATERIAL TABLE

Item	Description
Antenna Cover	ABS(Black)
Antenna Base	PC+PBT(Black)
Color Ring	PP(White)
Connector	SMA Plug(Black)
PCB	FR4
Sponge	Black
Cable	RG178 Cable;Brown

ELECTRICAL

Frequency: 863~928 MHz

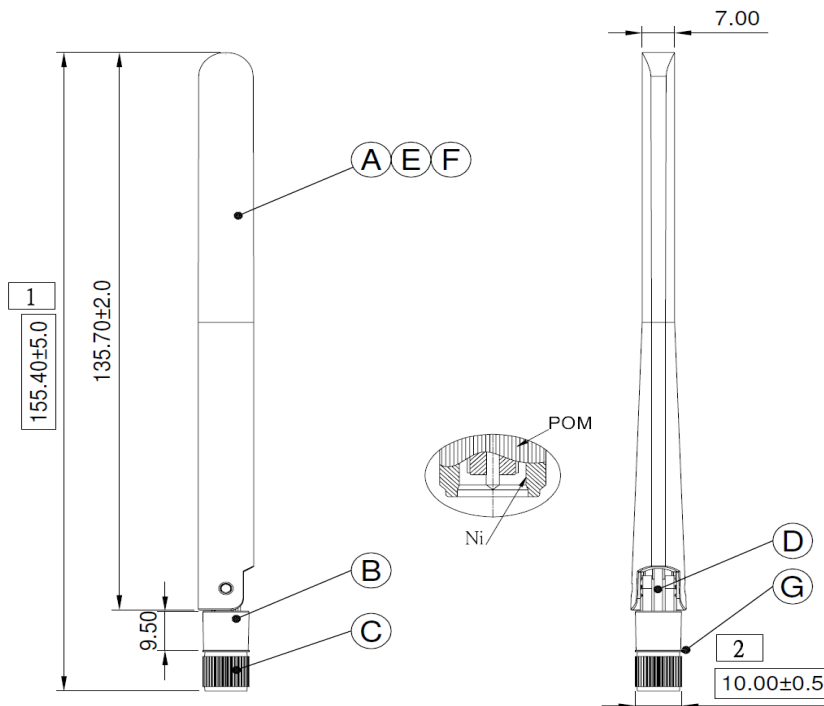

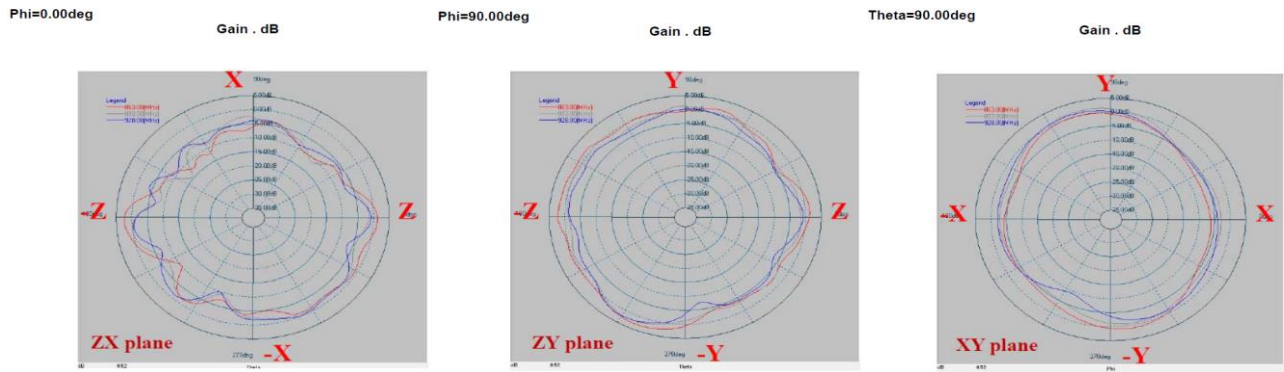

INFORMATION

For more information, please contact with
[Walsin Technology Corporation](http://www.walsin.com)
Tel : 886-3-475-8711
Fax : 886-3-475-5197
E mail : info@passivecomponent.com
Web Site : <http://www.passivecomponent.com>