

RF Product Information

■RFPCA791010IMRB301 Series for UHF Application at 863 ~ 870 MHz

Application

- UHF 863 ~ 870 MHz in Smart Meter, Industrial Data Acquisition System and Door Control System
- Device for external UHF system

Recommended Link Parts

RFCON030300IF6B002(On Board RF Connector)



ELECTRICAL CHARACTERISTICS


Item	Specification
Frequency Range	863 ~ 870 MHz
Impedance	50 Ohm Nominal
VSWR	2 Max.
Radiation	Omni-directional
Polarization	Linear Vertical
Admotted Power	1W

MATERIAL TABLE

Item	Description
Antenna	FR4(Black)
Connector	IPEX(Gold)
Double Tape	3M9888T
Cable	ψ 1.13 Cable;Black

ELECTRICAL

Frequency : 863~870 MHz

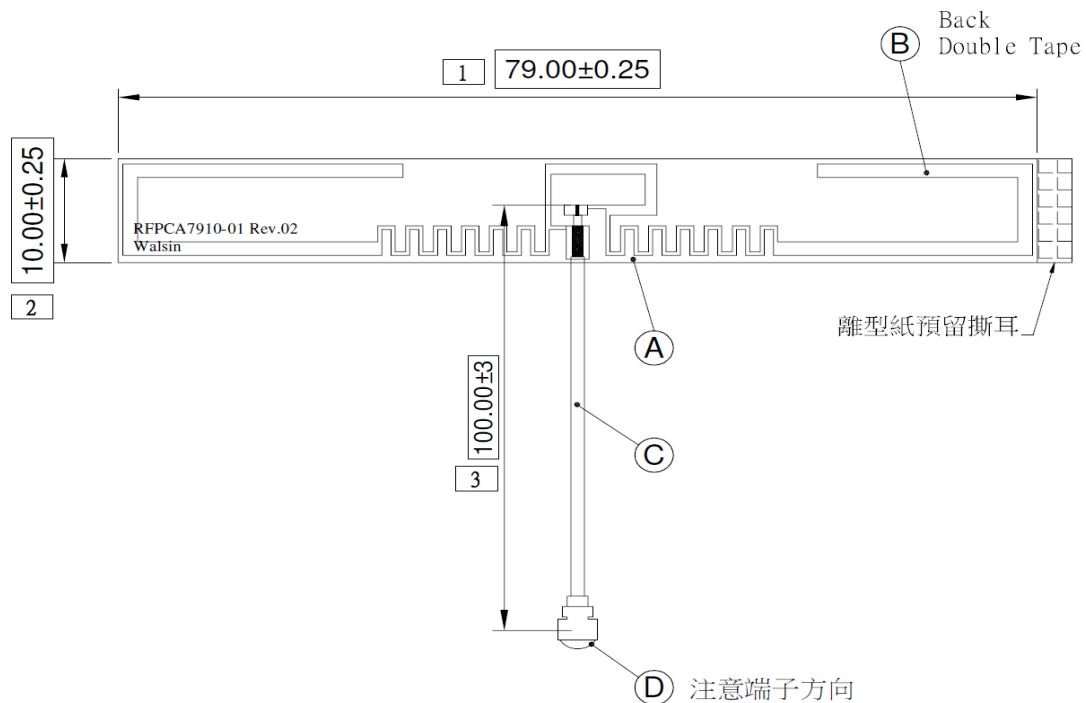

INFORMATION

For more information, please contact with
[Walsin Technology Corporation](http://www.walsin.com)
 Tel : 886-3-475-8711
 Fax : 886-3-475-5197
 E mail : info@passivecomponent.com
 Web Site : http://www.passivecomponent.com