


[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Find a Distributor / Rep](#)

[Home](#) / [Racks & Cabinets Accessories](#) / Non-Ventilated Sliding Shelf 22 x 14.25 inches

# Non-Ventilated Sliding Shelf

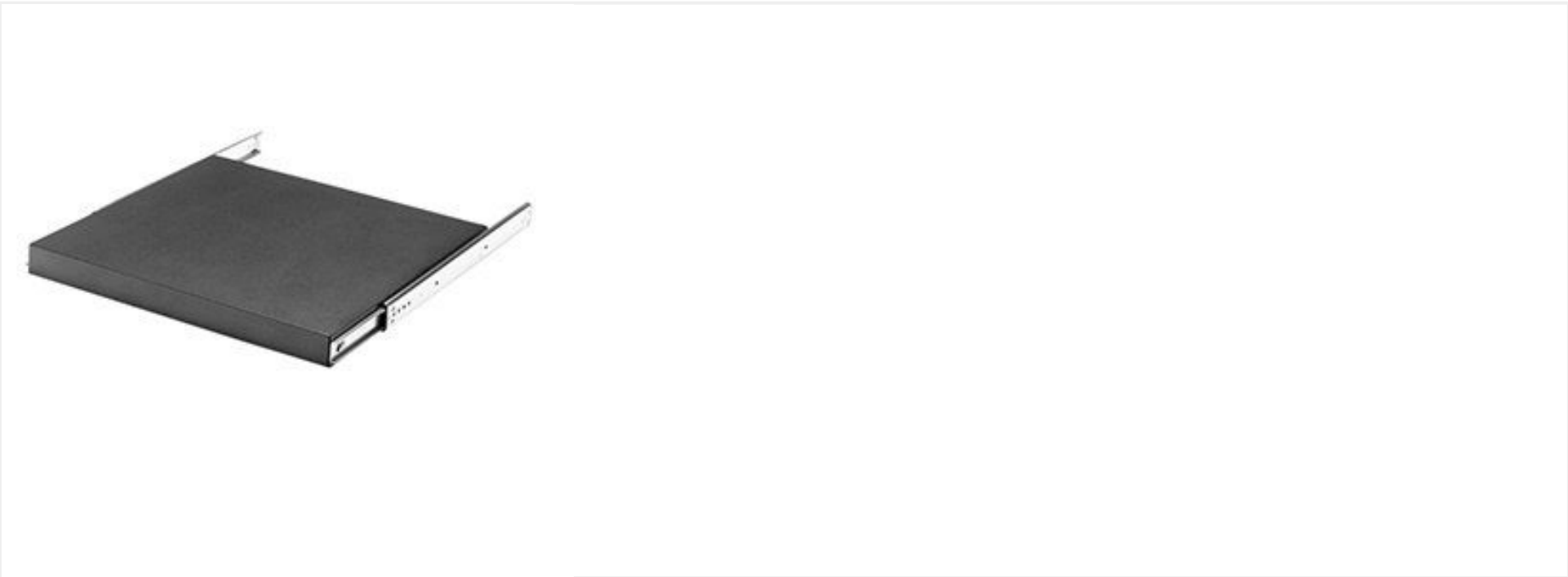

## Non-Ventilated Sliding Shelf 22 x 14.25 inches

Model # SH-2487

- Fits 24-inch-wide panel spaces with maximum clear inside depth of 17 inches
- Shelves are 16-gauge steel and flanged on all four sides for added support
- Universal mounting brackets allow flexibility in mounting
- Shelves allow sufficient room in rear for cables and power outlet strips
- Requires two pairs of panel mounting rails per cabinet rack
- Width: 22 inches
- Depth: 14.25 inches
- Load Rating: 140 pounds
- Travel: 8 inches
- Weight: 11.25 pounds
- Drawings [PDF](#) [DXF](#)



440-946-3200

Find Distributor/ Rep

Contact Us

[Warranty.](#)

[Privacy Policy.](#)

[Unsubscribe](#)

©2018 - 2023 BUD Industries, all rights reserved



?

Help