

[Check Stock/Pricing by Product No.](#)[Search By Size and Type](#)[Find a Distributor / Rep](#)

[Home](#) / [Products](#) / [General Use Boxes](#) / [Plasticase Style D Plastic Cases](#) / Plasticase Style D Plastic Case Gray PC-11482-LGA

Plasticase Style D Plastic Case Gray PC-11482-LGA



Model # PC-11482-LGA

[Plasticase Style D Plastic Cases](#)

- Light gray ABS covers with natural finish aluminum end panels
- UL94-HB flammability rating
- Suggested service temperature -40C to 80C
- Molded in card guides and mounting bosses

Compare Sizes and Models


[Request Modifications](#)

Check Stock / Pricing
External Size H x W x D: 2.56" x 10.24" x 7.09"
Internal Size H x W x D: 2.32" x 10.00" x 6.78" 
Weight: 1.11 lbs
Color: Light Gray
RoHS Certified: Always Compliant
Type of Plastic: ABS
Flammability Rating: UL94-HB
Service Temperature Low: -40
Service Temperature High: 80
Bosses: Yes
Card Guides: Yes



DRAWING



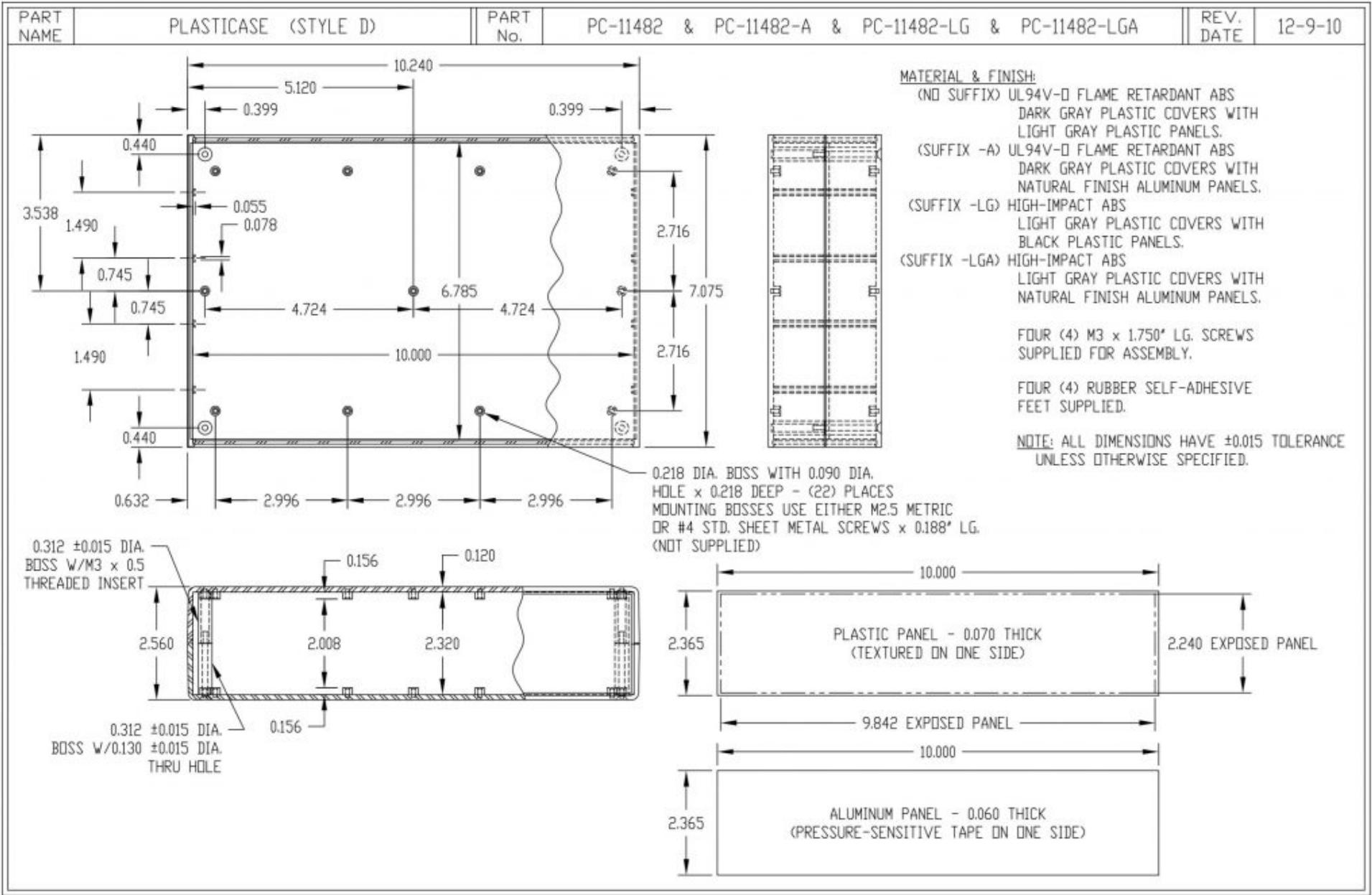

OTHER MODELS IN THIS SERIES

-- External Dimensions --

-- Internal Dimensions --

Model #	External Dimensions	Internal Dimensions
PC-11480	1.38" x 5.51" x 4.33"	1.18" x 5.32" x 4.07"
PC-11480-A	1.38" x 5.51" x 4.33"	1.18" x 5.32" x 4.07"
PC-11480-LG	1.38" x 5.51" x 4.33"	1.18" x 5.32" x 4.07"
PC-11480-LGA	1.38" x 5.51" x 4.33"	1.18" x 5.32" x 4.07"
PC-11481	1.57" x 8.86" x 6.50"	1.35" x 8.62" x 6.24"
PC-11481-A	1.57" x 8.86" x 6.50"	1.35" x 8.62" x 6.24"
PC-11481-LG	1.57" x 8.86" x 6.50"	1.35" x 8.62" x 6.24"
PC-11481-LGA	1.57" x 8.86" x 6.50"	1.35" x 8.62" x 6.24"
PC-11482	2.56" x 10.24" x 7.09"	2.32" x 10.00" x 6.78"
PC-11482-A	2.56" x 10.24" x 7.09"	2.32" x 10.00" x 6.78"
PC-11482-LG	2.56" x 10.24" x 7.09"	2.32" x 10.00" x 6.78"
PC-11482-LGA	2.56" x 10.24" x 7.09"	2.32" x 10.00" x 6.78"



440-946-3200 | Find Distributor/ Rep | Contact Us

Warranty Privacy Policy Unsubscribe ©2018 - 2023 BUD Industries, all rights reserved

