

ABS D 85 G



Sample image

Order symbol : ABS D 85 G

Product nr : 8784308

Description : Enclosure, ABS




Remarks : Grey cover

EAN : 6418074002174

El. number :

- Finland : 3423461
- Denmark : 8212001912
- Sweden : 2536717

Including : Base with screws for mounting plate/DIN-rail. cover with PUR gasket and polyamide cover screws.

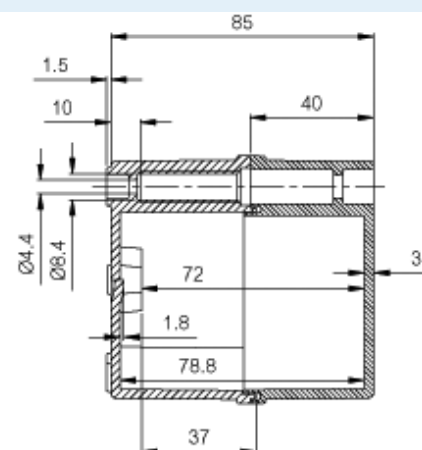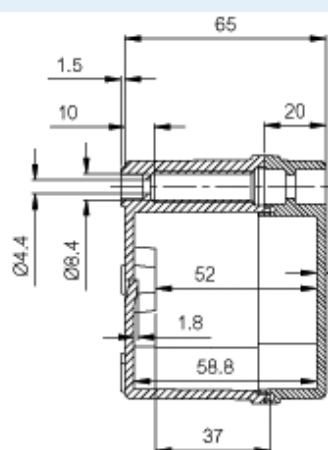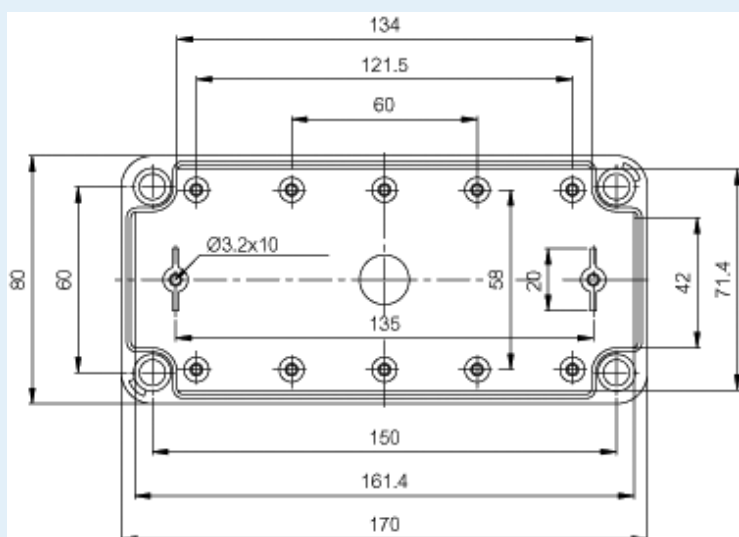

Dimensions :	Height	Width	Depth
--------------	--------	-------	-------

mm :	170	80	85
------	-----	----	----

inch :	6.69	3.15	3.35
--------	------	------	------

Materials :

Material :	ABS
Base colour :	RAL 7035 -light grey
Cover colour :	RAL 7035 -light grey
Gasket material :	Polyurethane

Accessories :

FP 22040	Wall fastening lug (2 pcs), for enclosures:
DH-3	DIN-35 Mounting rail, for enclosures: (140 x 35 x 1)
D-MP	Mounting plate, for enclosures: (140 x 54 x 1)

Ratings :

Ingress protection (EN 60529):	IP66; IP67;
Impact Resistance (EN 62262):	IK08;
electrical_insulation :	Totally insulated
Halogen free (DIN/VDE 0472, Part 815) :	Yes

Temperatures :

Temperature °C (short term) :	-40 ... 80
Temperature °F (short term) :	-40 ... 175
Temperature °F (continuous) :	-40 ... 140

UV resistance :	-
Flammability Rating :	UL 94 HB
Glow Wire Test (IEC 695-2-1) °C :	650C

Certificates :

SGSFIMKO_PICC_pc