

Product Datasheet

Product code: **15A.C.0**

Product type: Cutting tweezers

Made in: Switzerland

Description: Type 15A high precision cutting tweezers are suitable to applications which require cutting small material or performing small cuts. The strong blades are designed to apply moderate cutting force. Suitable to cut small, soft metal strands (e.g. Copper).

Tip description: angled, cutting, superior finish

Coating/finishing: Sandblasted

Body material: Carbon Steel (C)


Picture:



Tweezer dimensions:

| | |
|--------|-----------------------|
| OAL | 120.0 mm – 4.724 inch |
| Width | 12.0 mm – 0.472 inch |
| Height | 16.0 mm – 0.630 inch |

Tip details:

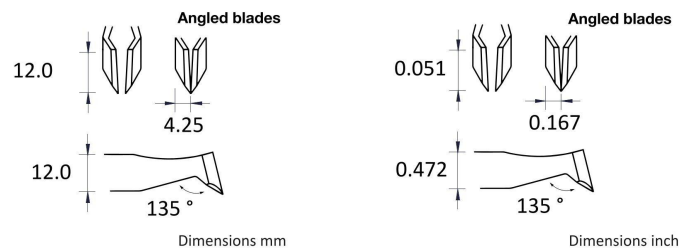

Tip dimensions:

| | |
|---------------|-----------------------|
| Tip width | 12.00 mm – 0.472 inch |
| Tip thickness | 4.25 mm – 0.167 inch |