


## EMMU-EMV 50

EMC-locknut, brass

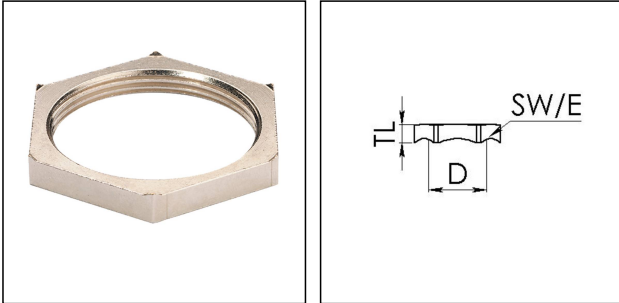

Products may differ in size, colour and appearance to those shown. If you require further information or customisation, please contact us directly.



<b>Material</b>	Brass nickel-plated
<b>Temp. range min</b>	-250 °C
<b>Temp. range max</b>	500 °C
<b>Thread type</b>	M
<b>Ø Connection thread D</b>	50
<b>Lead</b>	1,5
<b>Key width SW</b>	60 mm
<b>Collar diameter (E)</b>	65 mm
<b>Total length TL</b>	7 mm
<b>Surface</b>	Nickel-plated
<b>Order no. nickel-plated</b>	10063216
<b>Type</b>	EMMU-EMV 50
<b>Packing unit</b>	50
<b>Tariff number</b>	74153300
<b>ETIM-Classification</b>	EC000940

23.07.2023


Your Contact:

**WISKA UK Ltd.**

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

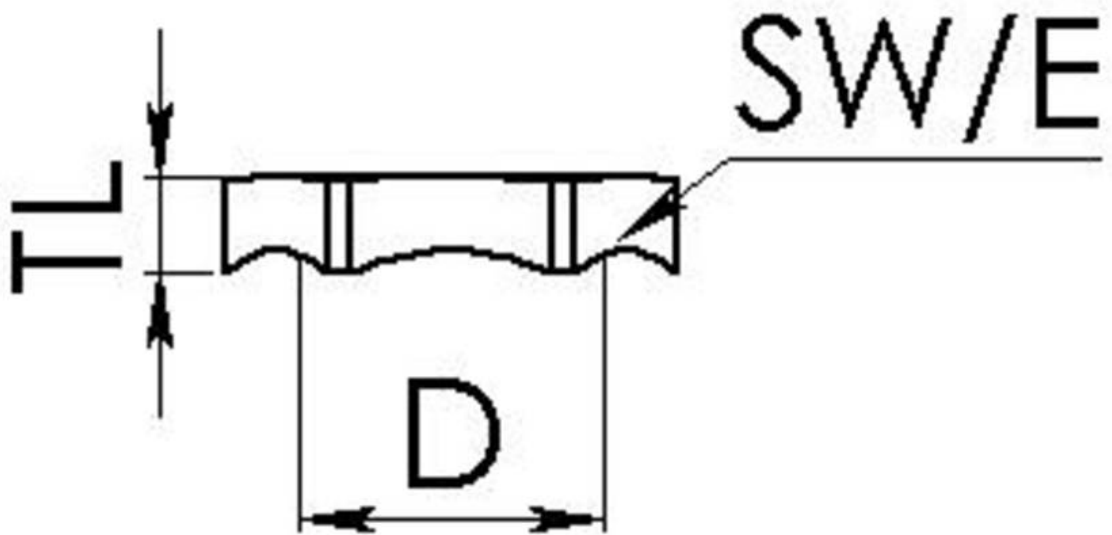

Your Contact:

**WISKA UK Ltd.**

Unit 7, Hurling Way · St. Columb Major Business Park · TR9 6SX, St. Columb Major, Cornwall · Great Britain

☎ +44-12-08816062 · 📠 +44-12-08816708

info@wiska.co.uk · www.wiska.co.uk

Other technical data on request / subject to change without notice