



/ Home / Products / Combination and multifunctional pliers / Lineman's Pliers, American style

09 15 240


Lineman's Pliers

American style



- High transmission ratio for easy cutting
- Requires 50 % less effort compared with conventional combination pliers thanks to optimal transmission ratio
- With fish tape puller in the joint gap
- With universal mandrel crimping point below the joint
- Solid construction for heaviest strain; universally applicable



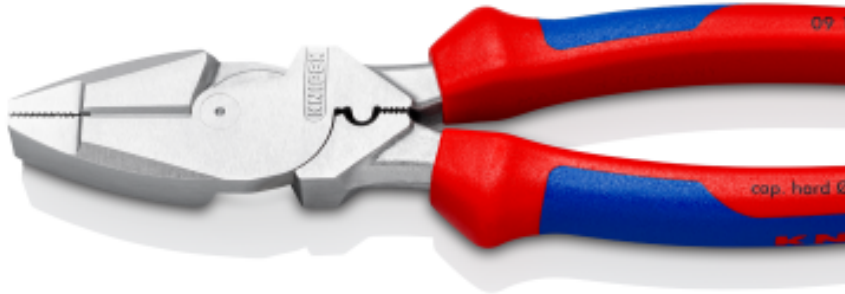

- Ergonomically optimised handle shape for firm contact to the hand and fatigue reducing operation
- Particularly effective cross-hatched knurled gripping zone in the jaws - for strong gripping and pulling
- Additional gripping zone below the joint for powerful leverage and pressing performance
- With cutting edges for soft and hard wire
- Cutting edges additionally induction-hardened, cutting edge hardness approx. 62 HRC





1/3

Technical attributes

Article No.	09 15 240
EAN	4003773087397
Pliers	chrome-plated
Head	chrome-plated
Handles	with multi-component grips
Weight	455 g
Dimensions	240 x 55 x 23 mm
Standard	DIN ISO 5746 ASME B107.20
REACH compliant	does not contain SVHC
RoHS compliant	not applicable



Cutting capacities medium hard wire (diameter)  Ø 4.6 mm

Schneidwerte harter Draht (Durchmesser) Ø 3.0 mm

All variations



09 01 240
Lineman's Pliers American
style
Length: 240 mm



09 02 240
Lineman's Pliers American
style
Length: 240 mm



09 02 240 T
Lineman's Pliers With
fastening eyelet American
style
Length: 240 mm



09 05 240
Lineman's Pliers American
style
Length: 240 mm



Length



1/7





Facebook



Instagram



Youtube



® LinkedIn



[Newsletter](#)

[Career](#)

[Contact](#)

[Terms and Conditions](#)

[Copyright](#)

[Imprint](#)

[Data protection](#)

[Privacy settings](#)