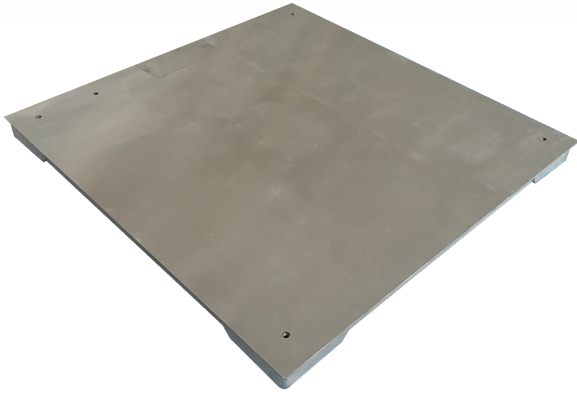# PT Stainless Steel Platforms with AE 403

ADAM®

PT stainless steel platform scales feature a grade 304 stainless steel pan and reinforced frame beneath the scale for additional support.

The platform boasts a IP66 rating alongside IP67-rated sealed load cells for advanced protection against dust and water ingress. The sleek brushed surface helps prevent the accumulation of food and dirt particles, making this scale ideal for weighing mining materials, food processing and chemical measurement.

This range includes the AE 403 indicator as standard, which has an IP67 rating and bracket included for mounting on walls and other vertical surfaces. The indicator offers an expanded range of weighing functions including checkweighing, parts counting, percentage weighing and display hold.

IP66-rated platform ideal for washdown environments

Features

- Rugged stainless steel construction for ultimate durability
- Approximately three-meter/10-foot shielded cable
- Can be used with any Adam indicators
- Heavy-duty rubber feet ensure stability of unit
- IP66-rated for protection against water and dust

Applications

- Weighing
- Parts counting
- Percentage weighing
- Checkweighing
- Dynamic / animal weighing
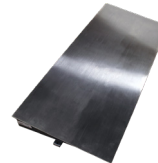

AE 403 Indicator

About ADAM:

For nearly 50 years, professionals worldwide have relied on Adam Equipment for an extensive selection of dependable and affordable weighing equipment. Adam provides the right balance of speed, performance and value.

PT Stainless Steel Platforms with AE 403

Model	PT 110S [AE403]	PT 310-5S [AE403]	PT 310-10S [AE403]	PT 112S [AE403]	PT 312-5S [AE403]	PT 312-10S [AE403]	PT 115S [AE403]	PT 315-5S [AE403]	PT 315-10S [AE403]
Capacity	2500lb / 1000kg	5000lb / 3000kg	10000lb / 4500kg	2500lb / 1000kg	5000lb / 3000kg	10000lb / 4500kg	2500lb / 1000kg	5000lb / 3000kg	10000lb / 4500kg
Readability	0.5lb / 0.2kg	1lb / 0.5kg	2lb / 1kg	0.5lb / 0.2kg	1lb / 0.5kg	2lb / 1kg	0.5lb / 0.2kg	1lb / 0.5kg	2lb / 1kg
Repeatability (S.D.)	1lb / 0.4kg	2lb / 1kg	4lb / 2kg	1lb / 0.4kg	2lb / 1kg	4lb / 2kg	1lb / 0.4kg	2lb / 1kg	4lb / 2kg
Linearity (+/-)	1lb / 0.4kg	2lb / 1kg	4lb / 2kg	1lb / 0.4kg	2lb / 1kg	4lb / 2kg	1lb / 0.4kg	2lb / 1kg	4lb / 2kg
Excitation Voltage	5 - 10 VAC / DC								
Loadcells	4								
Pan Size	39.4"x39.4" / 1000x1000mm			47.2"x47.2" / 1200x1200mm			59.1"x59.1" / 1500x1500mm		
Weighing Units	g, kg, lb, lb:oz, oz, N, custom unit								
Stabilization Time (sec)	2								
Interface	RS-232								
Calibration	External calibration								
Display	Backlit LCD with 1.6"/ 40mm -high digits								
Power Supply	12VDC 800mA adapter / Internal rechargeable battery								
Operating Temperature	-10° to 40°C / 14° to 104°F								
Housing	Stainless steel								
Cable Length	10' / 3M								
Overall Dim.	39.4"x39.4"x4.3" / 1000x1000x110mm (wxdxh)			47.2"x47.2"x4.3" / 1200x1200x110mm (wxdxh)			59.1"x59.1"x4.3" / 1500x1500x110mm (wxdxh)		
Net Weight	136.6lb / 62kg			174.1lb / 79kg			244.6lb / 111kg		

Accessories

Item number	Description
700100203	Stainless Steel Ramp - PT 12RS 1200mm wide
700100204	Stainless Steel Ramp - PT 15RS 1500mm wide
700100202	Stainless Steel Ramp - PT 10RS 1000mm wide
2050013351	Indicator stand
700660289	Calibration certificate

Key Accessories

Stainless Steel Ramp
Ideal for use with bench, floor and platform scales, Adam Equipment's ramps are constructed of stainless steel and facilitate loading and unloading heavy or oversized items such as drums, pallets and barrels.
.

Supplied by