

Offset screwdriver

 


207 Slotted offset screwdriver, with handle, DIN 5200.

For working in confined spaces.

Blade chrome-vanadium-molybdenum-special-steel, hardened, chrome-plated.

Handle high quality plastic, impact resistant, black, cadmium free.



3,5	90	8,5	0,6	3,5	12	10
-----	----	-----	-----	-----	----	----

4,0	100	9,0	0,8	4,0	15	10
-----	-----	-----	-----	-----	----	----

5,5	125	10,5	1,0	5,5	32	10
-----	-----	------	-----	-----	----	----


6,5 +	125	13,5	1,2	6,5	42	10
-------	-----	------	-----	-----	----	----

8,0	150	17,0	1,2	8,0	71	10
-----	-----	------	-----	-----	----	----

10,0	175	24,0	1,6	9,0	111	10
------	-----	------	-----	-----	-----	----

12,0	200	27,0	2,0	10,0	156	5
------	-----	------	-----	------	-----	---

+ Additional sizes to DIN dimensions.

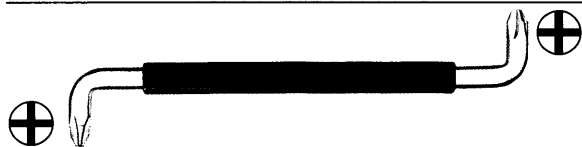

161 Phillips offset screwdriver, with handle, DIN 5208.

For working in confined spaces.

Blade chrome-vanadium-molybdenum-special-steel, hardened, chrome-plated.


Handle high quality plastic, impact resistant, black, cadmium free.



1 + 2	125	14,5	5,5	27	10
-------	-----	------	-----	----	----

2 + 3	150	21,0	8,0	76	10
-------	-----	------	-----	----	----

3 + 4	200	25,0	10,0	160	10
-------	-----	------	------	-----	----

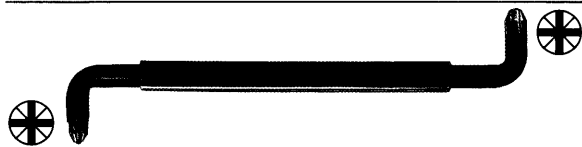

224 Pozidriv-Supadriv offset screwdriver, with handle.

For working in confined spaces.

Blade chrome-vanadium-molybdenum-special-steel, hardened, black finish.

Handle high quality plastic, impact resistant, black, cadmium free.




1 + 2	125	14,5	5,5	27	10
-------	-----	------	-----	----	----

2 + 3	150	21,0	8,0	76	10
-------	-----	------	-----	----	----

3 + 4	200	25,0	10,0	160	10
-------	-----	------	------	-----	----

Screw-holding drivers

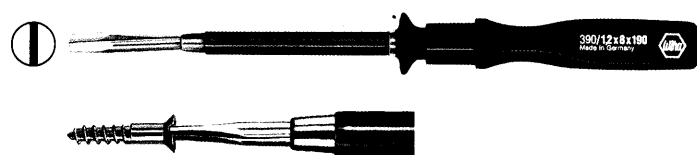

390 Slotted screw-holding screwdriver, with Wiha-square handle.

Split blade to hold screw.

Blade chrome-vanadium-steel, hardened, galvanized.

Sliding sleeve.

Wiha-square handle cellulose-acetate, impact resistant, red transparent, cadmium free.



0,4	5,0	90	175	85	22	46	5
-----	-----	----	-----	----	----	----	---

0,4	5,0	215	300	85	22	66	5
-----	-----	-----	-----	----	----	----	---

0,6	3,5	125	220	95	24	78	5
-----	-----	-----	-----	----	----	----	---

0,6	3,5	175	270	95	24	91	5
-----	-----	-----	-----	----	----	----	---

0,6	3,5	225	320	95	24	105	5
-----	-----	-----	-----	----	----	-----	---

0,6	5,5	125	220	95	24	78	5
-----	-----	-----	-----	----	----	----	---

0,6	5,5	175	270	95	24	82	5
-----	-----	-----	-----	----	----	----	---

0,6	5,5	225	320	95	24	102	5
-----	-----	-----	-----	----	----	-----	---


0,8	5,5	130	225	95	24	85	5
-----	-----	-----	-----	----	----	----	---

0,8	5,5	180	275	95	24	99	5
-----	-----	-----	-----	----	----	----	---

0,8	5,5	230	325	95	24	112	5
-----	-----	-----	-----	----	----	-----	---

1,2	8,0	190	295	105	28	135	5
-----	-----	-----	-----	-----	----	-----	---

1,2	8,0	235	340	105	28	155	5
-----	-----	-----	-----	-----	----	-----	---

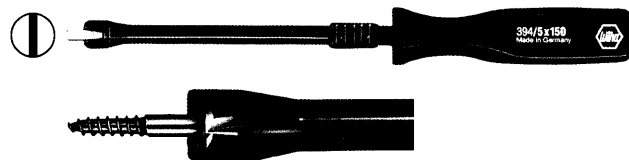


394 Slotted screw-holding screwdriver, with Wiha-square handle.

Clamping sleeve to hold screw.

Blade chrome-vanadium-molybdenum-steel, hardened, black finish, clamping sleeve polyamide.

 Wiha-square handle cellulose-acetate, impact resistant, red, cadmium free.



2,5	75	160	85	22	36	5
-----	----	-----	----	----	----	---

3,0	100	195	95	24	56	5
-----	-----	-----	----	----	----	---

4,0	125	230	105	28	85	5
-----	-----	-----	-----	----	----	---

5,0	150	265	115	32	122	5
-----	-----	-----	-----	----	-----	---

6,0	175	290	115	32	145	5
-----	-----	-----	-----	----	-----	---