

 **DEALER LOG IN**[About Us](#)[Product \(Index.Php?Do=Products\)](#)[Capability](#)[Acoustics \(Index.Php?Do=Technology&Tpid=5\)](#)[Applications](#)[Contact \(Contact\)](#)

 
Piezo Transducer (Passive Buzzer)

KMTG1612


Type / Terminal Shape : Piezo Transducer (Passive Buzzer)

Feature : High SPL, High / Low Temp Resistant

▶ 0:00 / 0:08

[🛒 INQUIRY](#)



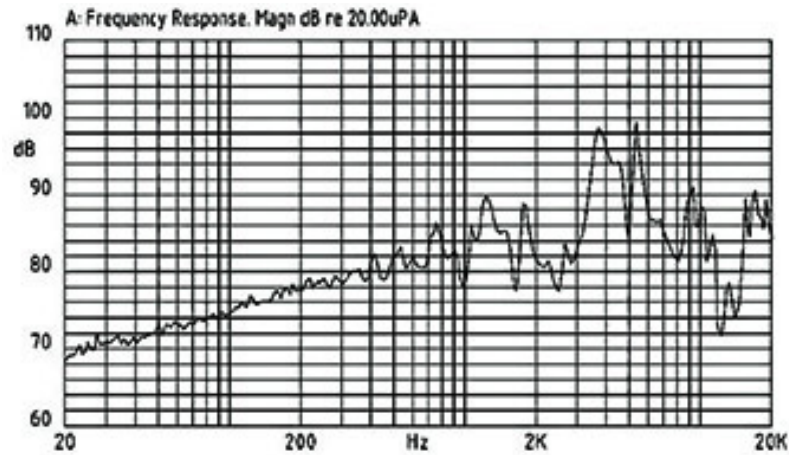

Size

Dimensions(mm) :	16.00*16.00*2.60
------------------	------------------

Electrical Characteristics

Frequency(Hz) :	4.0K
Max current consumption(mA) :	Max. 10.0@12Vp-p Square Wave. 4.0KHz
SPL(dB) :	Min. 90dB@10cm/12Vp-p Square Wave. 4.0KHz
Electrostatic Capacity (pF) :	20,000±30%@1KHz/1V
Tone :	Continuous

Others

Operation Temp.(°C) :	-40~120
Storage Temp.(°C) :	-40~+120
Material :	LCP(White) + PCB(FR4)



🏠 10F, No. 69-11, Sec.2, JhongJheng E. Rd., Danshui Dist, New Taipei City 251402, Taiwan

☎ +886-2-2809-5651

🖨 +886-2-2809-7151

✉ info@kingstate.com.tw

志豐電子 Kingstate Electronics Corp.

Kingstate is a well-known and leading acoustic manufacturer in Asia. We are dedicated to providing customers with high-quality products and professional sound solutions.

志豐地圖 Company Map

© 2019 Kingstate Electronics Corp. POWER by OZCHAMP (<https://www.ozchamp.com/>).