

Data Sheet | Item Number: 211-812

Nozzles; Length: 12 mm; For the use of 211-811; halogen-free; Cable outer diameter: 1.4 ... 5.0 mm; transparent

<https://www.wago.com/211-812>



Color: transparent

Technical data

Suitable	for wire diameter 1.4 ... 5 mm
Delivery form	Component
Properties	for one 211-811 marker
Printing device	Smart Printer (thermal transfer printer)

Physical data

Length	12 mm
Sheathed cable diameter	1.4 ... 5 mm

Mechanical data

Mounting type	Sliding on conductor
---------------	----------------------

Material data

Color	transparent
Material	Polyurethane
Adhesive information	without adhesive
Halogen-free	Yes
Weight	0.2 g
Fire load	0 MJ

Environmental requirements

Ambient temperature (storage)	+5 ... +40 °C
Ambient temperature (operation)	-40 ... +80 °C
Relative humidity	40 ... 80 %

Commercial data	
Product Group	2 (Terminal Block Accessories)
eCl@ss 10.0	27-40-04-01
eCl@ss 9.0	27-40-04-01
ETIM 8.0	EC001530
ETIM 7.0	EC001530
PU (SPU)	500 pcs
Packaging type	Box
Country of origin	IT
GTIN	4050821674986
Customs tariff number	39269097900

Environmental Product Compliance	
RoHS Compliance Status	Compliant, No Exemption

Downloads

Environmental Product Compliance

Compliance Search	
Environmental Product Compliance 211-812	

1 Compatible Products

1.1 Required Accessories

1.1.1 Marking

1.1.1.1 Marker



Item No.: 211-811
 Marker; for Smart Printer; for use in nozzles; Length: 12 mm; white


Installation Notes

Application



Slide the marker into the marking sleeve receptacle. Replacing the marker is also possible after the conductor has been terminated.

Application

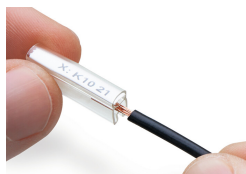

Compress the sleeve and slide it onto the conductor to be marked.