

Data sheet Actuator.


Part No.: 18-287.035

Technical data




Design	flush
Front form	square
Front dimension	19 mm x 19 mm
Terminal	Soldering terminal
Operating Travel	ca. 2.2 mm ± 0,2 mm
Lens illumination	illuminative
Front bezel colour	Black
Front bezel material	Plastic
Housing colour	Black
Housing material	Plastic
Weight	0.002 kg
IP front protection	IP40, according to IEC 60529
Contact material	Gold
Switching action	Maintained
Switching system	Snap-action switching element
Internal size	13,8 mm x 13,8 mm
Contacts	1 NO
Operating temperature	- 25 °C ... + 65 °C
Operating force	1.4 N
Mechanical lifetime	1 Mio. cycles of operation
Tightening torque	Fixing nut max. 0.2 Nm


Dimension drawings

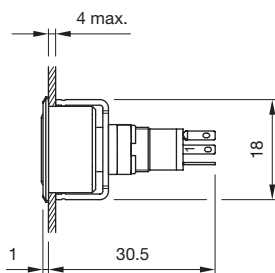

Mounting cut-outs

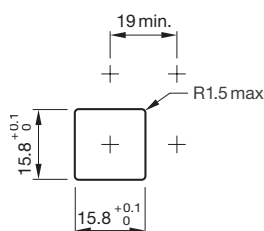

Wiring diagrams

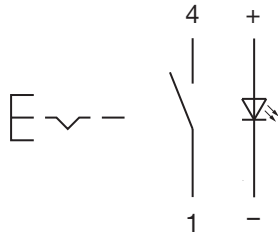

Component layouts


 

(A)

(B)

9 x 9 mm
19 x 19 mm

9 x 14 mm

Ø9 mm
Ø19 x 19 mm

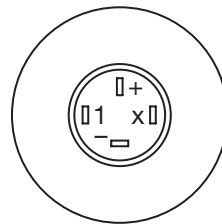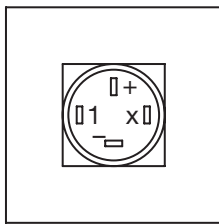

(C)

(D)

(E)

- A = Terminals (rear side)
- B = Illuminated pushbutton
- C = x = Contact No.
- D = 2 = Normally open
- E = 4 = Normally close