

# Data sheet Actuator.


## Part No.: 19-139.035

### Technical data




Design	raised
Front dimension	Ø 9 mm
Terminal	Plug-in terminal, 2 x 0.5 mm
Operating Travel	ca. 2.8 mm ± 0,2 mm
Lens illumination	illuminative
Front bezel colour	Black
Front bezel material	Plastic
Housing colour	Black
Housing material	Plastic
Weight	0.002 kg
IP Protection	IP40 front side, according to DIN EN 60529
Contact material	Gold
Switching action	Momentary
Switching system	Snap-action switching element
Switching rating	50 V @ 0,1 A
Internal size	Ø 7,3 mm
Contacts	1 NO
Operating temperature	- 25 °C ... + 45 °C with filament lamp, - 25 °C ... + 65 °C with LED, - 25 °C ... + 65 °C without illumination, mounted as a block, make sure the heat can escape freely
Operating force	1.6 N
Mechanical lifetime	2 Mio. cycles of operation
Tightening torque	Fixing nut max. 0.2 Nm


### Dimension drawings

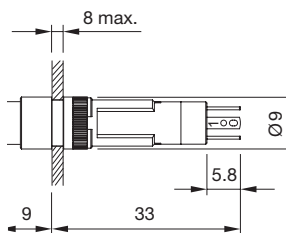

### Mounting cut-outs

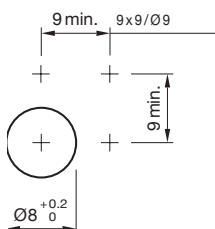

Wiring diagrams


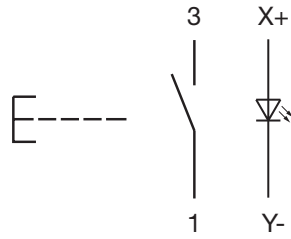


Component layouts



9 x 9 mm

Ø9 mm

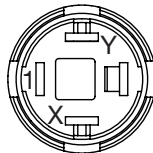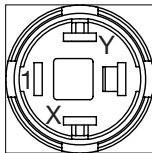

A = Terminals (rear side)  
 B = Illuminated pushbutton  
 C = x = Contact No.  
 D = 2 = Normally open  
 E = 4 = Normally close