


PXM06006MANBK4868 Datasheet

Product Name // Black Anodised Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male

[View Product Page](#)

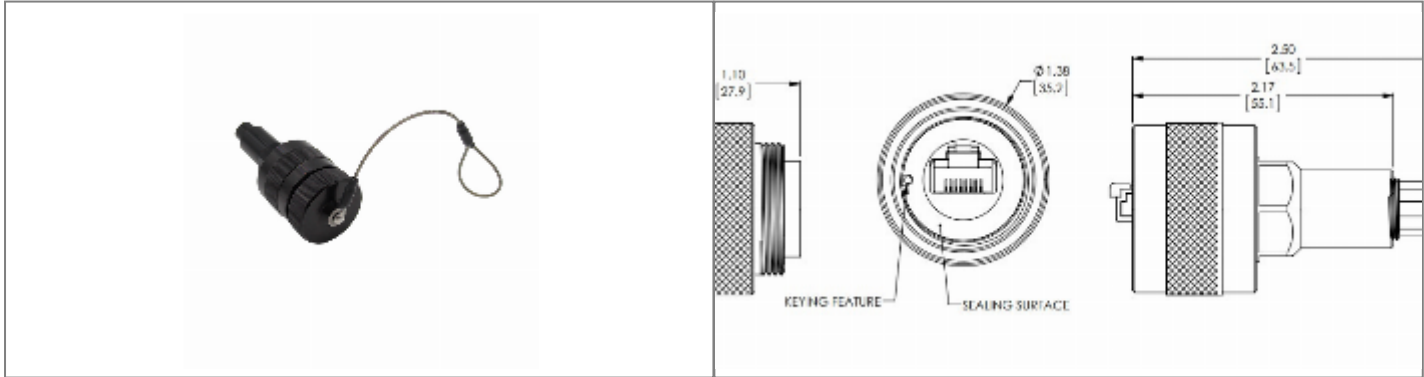

// Product Description:

- ⊗ Black Anodised Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male
- ⊗ IP68 rated when mated
- ⊗ Crimp Terminals
- ⊗ Durability >500 cycles
- ⊗ Operating temperature -40Â°C to +100Â°C
- ⊗ Supports 10, 100 and 1,000 Mbps data transmissions
- ⊗ POE, POE+, and POE++
- ⊗ Hardware: Stainless Steel, Seals: Silicone, Lanyard: Stainless Steel (Nylon coated & 6.0" length)

// General Information:

Product Display Title:	Black Anodised Aluminium Plug Connector with Cap - Cable Entry: 4.82-6.85mm - Cat6a Male
Product Family:	Circular Data Connectors
Product Series:	600 Series - Ethernet Buccaneer Connectors
Body Colour:	Black
Body Length:	61.7mm
Body Material:	Aluminium
Body Material Type:	Metal Body
Connection Method:	Crimp
Contact Type:	Male
Coupling Type:	Screw
Diameter Over Coupling Ring Mm:	35mm
Durability:	>500 cycles
Ethernet Category:	Cat 6a
Function:	Plug Connector
Ip Rating:	IP68
Material Finish:	Anodised
Max Cable Entry Size:	6.88mm
Min Cable Entry Size:	4.83mm
Min Operating Temperature:	-40°C
Operating Humidity:	43°C - 98%
Max Operating Frequency:	+100°C
Rohs Compliant:	Yes
Salt Spray Corrosion Test:	500hr
Shock Resistance:	100G - 6ms

// Product PDF Links

[Standard Series USB connectors...](#)

// Product 3D CAD Model Links

[PXM06006MANBK48683D CAD Model](#)