



MASTER Glass LED bulbs

MAS LEDBulbDT3.4-40WB22 927A60CL G UK

Featuring a classic heritage design, these filament MASTER glass bulbs combine the familiar shapes of incandescent glass LED bulbs with the benefits of long-lasting LED technology. Ideal for creating a cosy atmosphere for customers, these glass LED bulbs provide excellent quality of light. MASTER glass bulbs can be dimmed for different lumen levels and colour temperatures (dimmable glass led bulbs). They also deliver significant energy savings, using 30% less energy compared to normal LED bulbs. By offering a lifetime of 25,000 hours, these dimmable glass LED bulbs also reduce maintenance costs.

Product data

General information	
Lighting Technology	LED
Flux measurement reference	Sphere
Switching Cycle	20,000
Nominal lifetime	25,000 h
Cap base	B22 [B22]
Light technical	
Colour Code	922-927 [CCT of 2200K-2700K]
Luminous Flux	470 lm
Colour designation	Warm Glow (WG)
Correlated Colour Temperature	2200 2700 K
Luminous Efficacy (rated) (Nom)	138 lm/W
Colour consistency	<6
Colour rendering index (CRI)	90
LLMF at end of nominal lifetime (nom.)	70 %
Flickering value (PstLM)	0.9

Stroboscopic effect	0.4
Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	3.4 W
Lamp current (nom.)	24 mA
Wattage equivalent	40 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.6
Voltage (nom.)	220-240 V
Temperature	
Ambient temperature range	-20°C to 45°C
T-Case maximum (nom.)	70 °C

MASTER Glass LED bulbs

Controls and dimming

Dimmable	Only with specific dimmers
----------	----------------------------

Mechanical and housing

Lamp Finish	Clear
Bulb material	Glass
Bulb shape	A60 [A 60 mm]


Approval and application

Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	4 kWh
EPREL registration number	1109130
EU RoHS compliant	Yes

Product data


Full EOC	871951446655500
Order product name	MAS LEDBulbDT3.4-40WB22 927A60CL G UK
Order code	46655500
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003010142
Full product name	MAS LEDBulbDT3.4-40WB22 927A60CL G UK
EAN/UPC – Case	8719514466562

Dimensional drawing

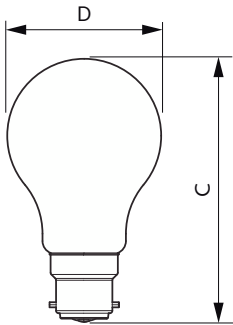


Product	D	C
MAS LEDBulbDT3.4-40WB22 927A60CL G UK	60 mm	103 mm

Photometric data

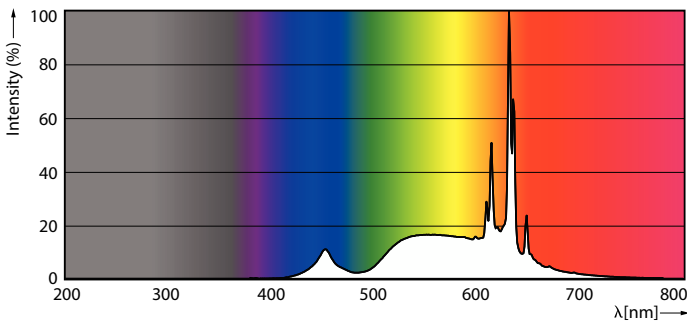


Spectral Power Distribution Colour - MAS LEDBulbDT3.4-40WB22 927A60CL G UK

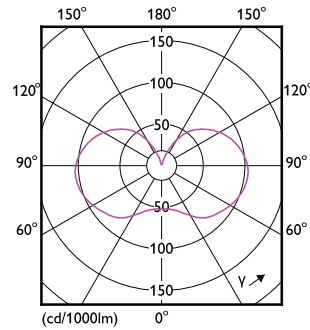

Light Distribution Diagram - MAS LEDBulbDT3.4-40WB22 927A60CL G UK

MASTER Glass LED bulbs

Photometric data

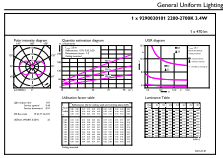


General uniform lighting - MAS LEDBulbDT3.4-40WB22 927A60CL G UK

Lifetime



Life Expectancy Diagram - MAS LEDBulbDT3.4-40WB22 927A60CL G UK

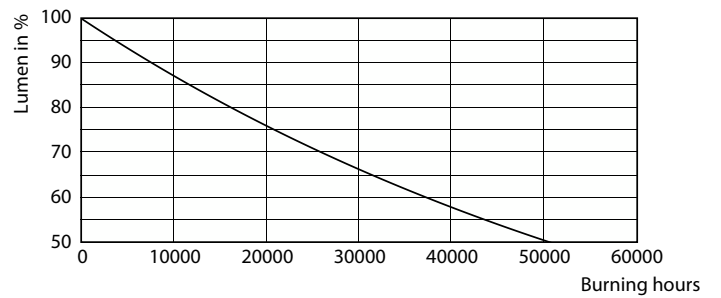

Lumen Maintenance Diagram - MAS LEDBulbDT3.4-40WB22 927A60CL G UK

