



# MASTER Glass LED bulbs

## MAS LEDBulbDT5.9-60W E27 927A60CL G UK

Featuring a classic heritage design, these filament MASTER glass bulbs combine the familiar shapes of incandescent glass LED bulbs with the benefits of long-lasting LED technology. Ideal for creating a cosy atmosphere for customers, these glass LED bulbs provide excellent quality of light. MASTER glass bulbs can be dimmed for different lumen levels and colour temperatures (dimmable glass led bulbs). They also deliver significant energy savings, using 30% less energy compared to normal LED bulbs. By offering a lifetime of 25,000 hours, these dimmable glass LED bulbs also reduce maintenance costs.

### Product data


General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	25,000 h	Input frequency	50 to 60 Hz
Cap base	E27 [E27]	Power Consumption	5.9 W
Light technical		Lamp current (nom.)	40 mA
Colour Code	922-927 [CCT of 2200K-2700K]	Wattage equivalent	60 W
Luminous Flux	806 lm	Starting time (nom.)	0.5 s
Colour designation	Warm Glow (WG)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2200 2700 K	Power Factor (Fraction)	0.6
Luminous Efficacy (rated) (Nom)	136 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	90	Ambient temperature range	-20°C to 45°C
LLMF at end of nominal lifetime (nom.)	70 %	T-Case maximum (nom.)	70 °C
Flickering value (PstLM)	0.9		

# MASTER Glass LED bulbs

Controls and dimming	
Dimmable	Only with specific dimmers
Mechanical and housing	
Lamp Finish	Clear
Bulb material	Glass
Bulb shape	A60 [A 60 mm]
Approval and application	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	6 kWh
EPREL registration number	1109131
EU RoHS compliant	Yes


Product data	
Full EOC	871951446657900
Order product name	MAS LEDBulbDT5.9-60W E27 927A60CL G UK
Order code	46657900
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003010342
Full product name	MAS LEDBulbDT5.9-60W E27 927A60CL G UK
EAN/UPC – Case	8719514466586

## Dimensional drawing

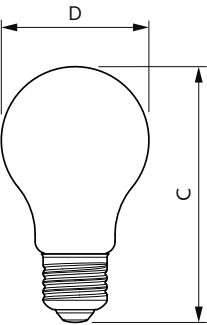


Product	D	C
MAS LEDBulbDT5.9-60W E27 927A60CL G UK	60 mm	104 mm

## Photometric data

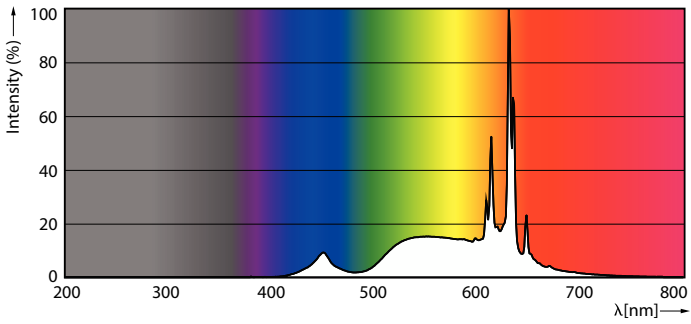


Spectral Power Distribution Colour - MAS LEDBulbDT5.9-60W E27 927A60CL G UK

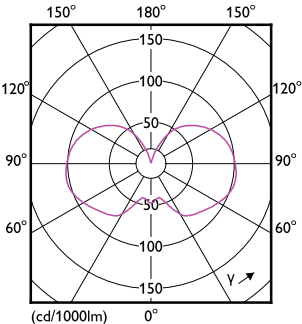

Light Distribution Diagram - MAS LEDBulbDT5.9-60W E27 927A60CL G UK

## MASTER Glass LED bulbs


### Photometric data

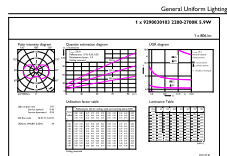


Cellulose Phosphates 4.5	Polysulfone 6.5	Form. 5.5
--------------------------	-----------------	-----------

General uniform lighting - MAS LEDBulbDT5.9-60W E27 927A60CL G UK

## Lifetime

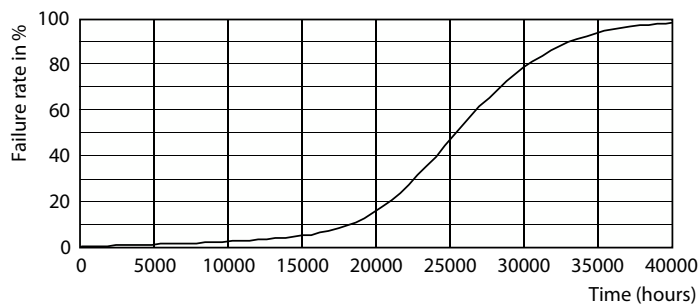

Life Expectancy Diagram - MAS LEDBulbDT5.9-60W E27 927A60CL G UK

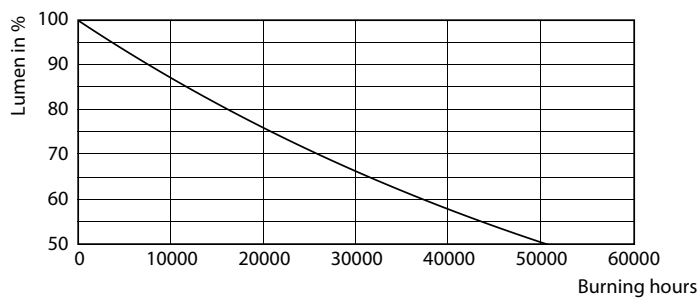

**Lumen Maintenance Diagram - MAS LEDBulbDT5.9-60W E27 927A60CL G**  
**UK**

