



# CorePro Glass LED bulbs

## CorePro LEDBulbND 8.5-75W E27 A60 827CLG

Featuring a classic heritage design, these filament LED lamps combine the familiar shapes of classic incandescent bulbs with the benefits of long-lasting LED technology. A very easy choice for people who are looking for a retrofit LED replacement, these CorePro LED bulbs provide 90% energy savings compared with conventional lamps. CorePro Glass LED bulbs provide excellent quality of light in a vintage style. CorePro LED lighting that offers a lifetime of 15,000 hours to reduce maintenance costs.

### Product data

General information		Stroboscopic effect	
Lighting Technology	LED		0.4
Flux measurement reference	Sphere	Operating and electrical	
Switching Cycle	20,000	Line Frequency	50 to 60 Hz
Nominal lifetime	15,000 h	Input frequency	50 to 60 Hz
Cap base	E27 [E27]	Power Consumption	8.5 W
Light technical		Lamp current (nom.)	70 mA
Colour Code	827 [CCT of 2700K]	Wattage equivalent	75 W
Luminous Flux	1,055 lm	Starting time (nom.)	0.5 s
Colour designation	Warm White (WW)	Warm-up time to 60% light	0.5 s
Correlated Colour Temperature	2700 K	Power Factor (Fraction)	0.52
Luminous Efficacy (rated) (Nom)	124.00 lm/W	Voltage (nom.)	220-240 V
Colour consistency	<6	Temperature	
Colour rendering index (CRI)	80	T-Case maximum (nom.)	50 °C
LLMF at end of nominal lifetime (nom.)	70 %		
Flickering value (PstLM)	1		

# CorePro Glass LED bulbs

## Controls and dimming

Dimmable	No
----------	----

## Mechanical and housing

Lamp Finish	Clear
Bulb shape	A60 [A 60 mm]


## Approval and application

Energy Efficiency Class	E
Energy consumption kWh/1,000 hours	9 kWh
EPREL registration number	387423
CE mark	Yes
EU RoHS compliant	Yes

## Product data


Full EOC	871951434712000
Order product name	CorePro LEDBulbND 8.5-75W E27 A60 827CLG
Order code	34712000
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929002025492
Full product name	CorePro LEDBulbND 8.5-75W E27 A60 827CLG
EAN/UPC – Case	8719514347137

## Dimensional drawing

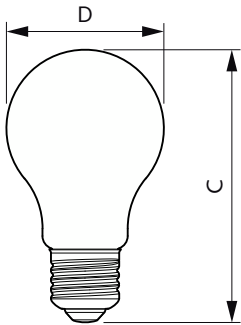


Product	D	C
CorePro LEDBulbND 8.5-75W E27 A60 827CLG	60 mm	104 mm

## Photometric data

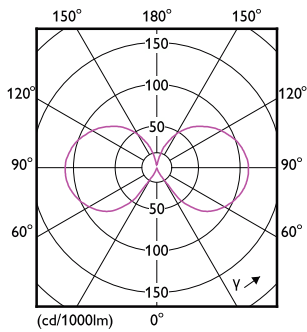

Light Distribution Diagram - CorePro LEDBulbND 8.5-75W E27 A60 827CLG

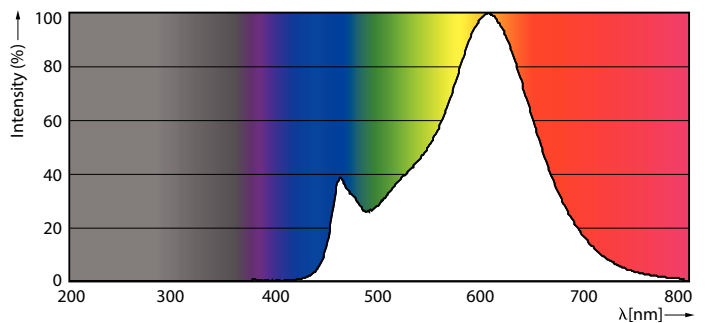

Spectral Power Distribution Colour - CorePro LEDBulbND 8.5-75W E27 A60 827CLG

# CorePro Glass LED bulbs


## Photometric data




© Philips Lighting B.V. 2023

General uniform lighting - CorePro LEDBulbND 8.5-75W E27 A60 827CLG

## Lifetime

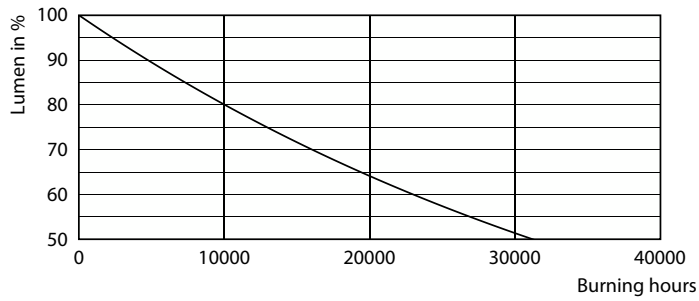

Lumen Maintenance Diagram - CorePro LEDBulbND 8.5-75W E27 A60 827CLG

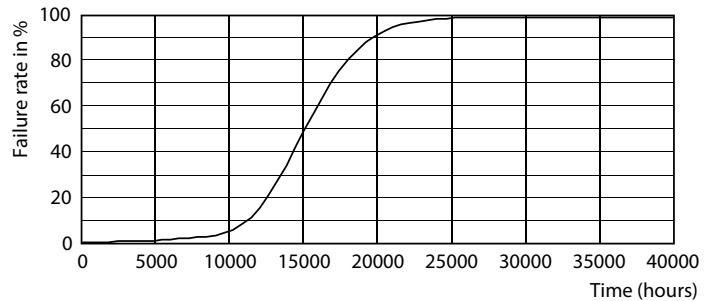

Life Expectancy Diagram - CorePro LEDBulbND 8.5-75W E27 A60 827CLG

