



MASTER Value Glass LED bulbs

MASTER VLE LEDBulbD3.4-40W E27 927 A60 FR G

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimmable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

Product data


General information		Colour rendering index (CRI)	
Lighting Technology	LED		90
Flux measurement reference	Sphere	LLMF at end of nominal lifetime (nom.)	70 %
Switching Cycle	20,000	Flickering value (PstLM)	1
Nominal lifetime	15,000 h	Stroboscopic effect	0.4
Cap base	E27 [E27]		
Light technical		Operating and electrical	
Colour Code	927 [CCT of 2700K]	Line Frequency	50 to 60 Hz
Luminous Flux	470 lm	Input frequency	50 to 60 Hz
Colour designation	Warm White (WW)	Power Consumption	3.4 W
Correlated Colour Temperature	2700 K	Lamp current (nom.)	20 mA
Luminous Efficacy (rated) (Nom)	138.00 lm/W	Wattage equivalent	40 W
Colour consistency	<6	Starting time (nom.)	0.5 s
		Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.7

MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
Temperature	
T-Case maximum (nom.)	80 °C
Controls and dimming	
Dimmable	Only with specific dimmers
Mechanical and housing	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
Approval and application	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	4 kWh
EPREL registration number	574384



CE mark	Yes
EU RoHS compliant	Yes
Product data	
Full EOC	871951435483800
Order product name	MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G
Order code	35483800
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003070702
Full product name	MASTER VLE LEDBulbD3.4-40W E27 927 A60 FR G
EAN/UPC - Case	8719514354845

Dimensional drawing

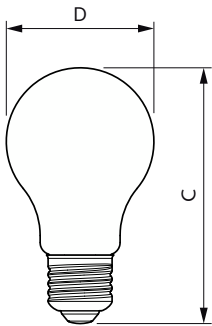

Product	D	C
MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G	60 mm	104 mm

Photometric data

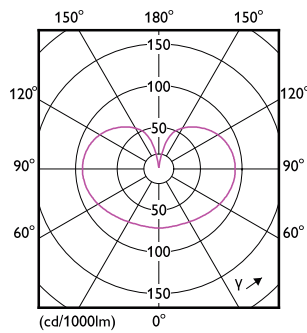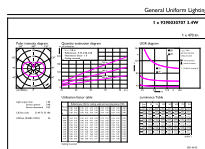


General uniform lighting - MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G

Light Distribution Diagram - MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G

MASTER Value Glass LED bulbs

Photometric data

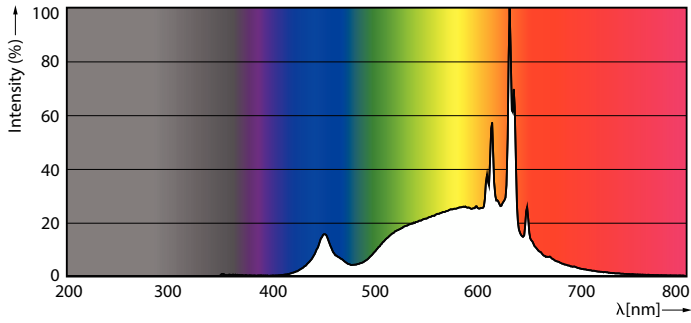


Spectral Power Distribution Colour - MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G

Lifetime



Life Expectancy Diagram - MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G

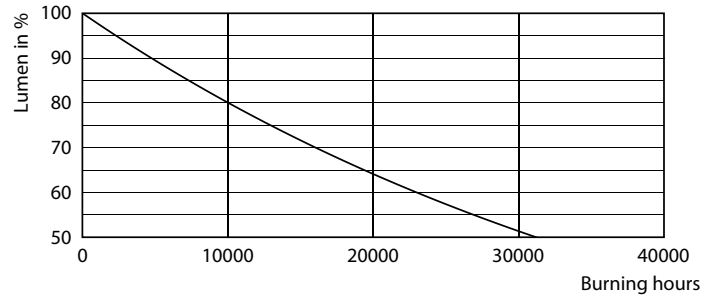

Lumen Maintenance Diagram - MAS VLE LEDBulbD3.4-40W E27 927 A60 FR G

