



MASTER Value Glass LED bulbs

MASTERVLELED Bulb D5.9-60W E27 927A60FR G UK

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimmable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

Product data

General information	
Lighting Technology	LED
Switching Cycle	20,000
Nominal lifetime	15,000 h
Cap base	E27 [E27]

Light technical	
Colour Code	927 [CCT of 2700K]
Luminous Flux	806 lm
Colour designation	Warm White (WW)
Correlated Colour Temperature	2700 K
Luminous Efficacy (rated) (Nom)	136.00 lm/W
Colour consistency	<6
Colour rendering index (CRI)	90

LLMF at end of nominal lifetime (nom.)	70 %
Flickering value (PstLM)	1
Stroboscopic effect	0.4


Operating and electrical	
Line Frequency	50 to 60 Hz
Input frequency	50 to 60 Hz
Power Consumption	5.9 W
Lamp current (nom.)	35 mA
Wattage equivalent	60 W
Starting time (nom.)	0.5 s
Warm-up time to 60% light	0.5 s
Power Factor (Fraction)	0.7

MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
Temperature	
T-Case maximum (nom.)	80 °C
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
Approval and application	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	6 kWh
EPREL registration number	574362



EU RoHS compliant	Yes
Product data	
Full EOC	871951434786101
Order product name	MASVLELEDBulb D5.9-60W E27 927A60FR G UK
Order code	34786101
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003057799
Full product name	MASTERVLELEDBulb D5.9-60W E27 927A60FR G UK
EAN/UPC - Case	8719514405233

Dimensional drawing

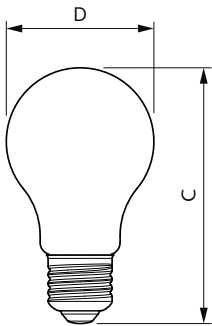

Product	D	C
MASVLELEDBulb D5.9-60W E27 927A60FR G UK	60 mm	104 mm

Photometric data

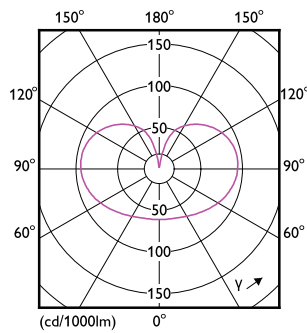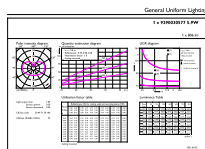


General uniform lighting - MASVLELEDBulb D5.9-60W E27 927A60FR G UK

Light Distribution Diagram - MASVLELEDBulb D5.9-60W E27 927A60FR G UK

MASTER Value Glass LED bulbs

Photometric data

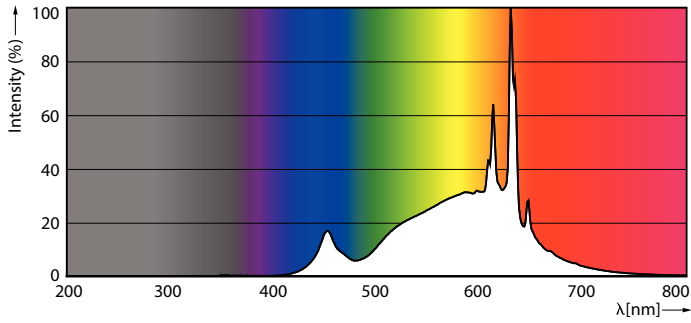

Spectral Power Distribution Colour - MASVLELED Bulb D5.9-60W E27 927A60FR G UK

Lifetime



Life Expectancy Diagram - MASVLELED Bulb D5.9-60W E27 927A60FR G UK



Lumen Maintenance Diagram - MASVLELED Bulb D5.9-60W E27 927A60FR G UK

