



# MASTER Value Glass LED bulbs



## MASTER VLE LEDBulbD11.2-100W E27 927 A60FRG

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimmable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

### Product data


General information		Colour rendering index (CRI)	
Lighting Technology	LED		90
Flux measurement reference	Sphere	LLMF at end of nominal lifetime (nom.)	70 %
Switching Cycle	20,000	Flickering value (PstLM)	1
Nominal lifetime	15,000 h	Stroboscopic effect	0.4
Cap base	E27 [E27]		
Light technical		Operating and electrical	
Colour Code	927 [CCT of 2700K]	Line Frequency	50 to 60 Hz
Luminous Flux	1,521 lm	Input frequency	50 to 60 Hz
Colour designation	Warm White (WW)	Power Consumption	11.2 W
Correlated Colour Temperature	2700 K	Lamp current (nom.)	51 mA
Luminous Efficacy (rated) (Nom)	135.00 lm/W	Wattage equivalent	100 W
Colour consistency	<6	Starting time (nom.)	0.5 s
		Warm-up time to 60% light	0.5 s
		Power Factor (Fraction)	0.7

# MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
<b>Temperature</b>	
T-Case maximum (nom.)	80 °C
<b>Controls and dimming</b>	
Dimmable	Only with specific dimmers
<b>Mechanical and housing</b>	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
<b>Approval and application</b>	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	12 kWh
EPREL registration number	574366



CE mark	Yes
EU RoHS compliant	Yes
<b>Product data</b>	
Full EOC	871951434794600
Order product name	MAS VLE LEDBulbD11.2-100W E27 927 A60FRG
Order code	34794600
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003058502
Full product name	MASTER VLE LEDBulbD11.2-100W E27 927 A60FRG
EAN/UPC - Case	8719514347953

## Dimensional drawing

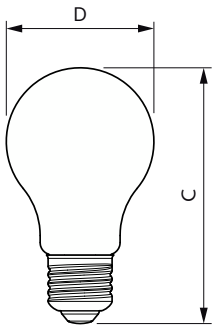

Product	D	C
MAS VLE LEDBulbD11.2-100W E27 927 A60FRG	60 mm	108 mm

## Photometric data

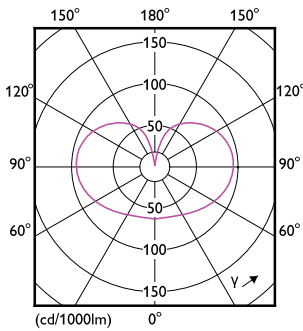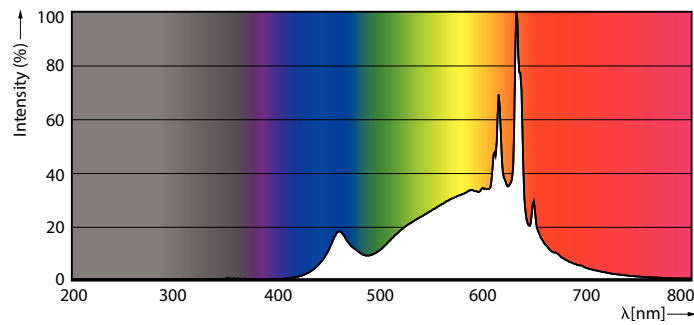

Spectral Power Distribution Colour - MAS VLE LEDBulbD11.2-100W E27 927 A60FRG

Light Distribution Diagram - MAS VLE LEDBulbD11.2-100W E27 927 A60FRG

