



MASTER Value Glass LED bulbs

MASTERVLE LEDBulbD10.5-100W B22A60 927FRGUK

Featuring a classic heritage design, these filament LED bulbs combine the familiar shapes of incandescent bulbs with the benefits of long-lasting LED technology. These MASTER Value Glass LED bulbs offer more energy savings than normal glass LED bulbs. At the same time, they also provide customers with good light experience, enhanced by excellent dimming performance (dimnable glass LED bulbs). MASTER Value Glass LED Bulbs deliver significant energy savings, using 30% less energy compared to normal LED bulbs and provide excellent quality of light. By offering a lifetime of 15,000 hours, these dimmable LED bulbs also reduce maintenance costs.

Product data


General information		LLMF at end of nominal lifetime (nom.) 70 %	
Lighting Technology	LED	Flickering value (PstLM)	0.9
Switching Cycle	20,000	Stroboscopic effect	0.35
Nominal lifetime	15,000 h	Operating and electrical	
Cap base	B22 [B22]	Line Frequency	50 to 60 Hz
Light technical		Input frequency	50 to 60 Hz
Colour Code	927 [CCT of 2700K]	Power Consumption	10.5 W
Luminous Flux	1,521 lm	Lamp current (nom.)	55 mA
Colour designation	Warm White (WW)	Wattage equivalent	100 W
Correlated Colour Temperature	2700 K	Starting time (nom.)	0.5 s
Luminous Efficacy (rated) (Nom)	144.00 lm/W	Warm-up time to 60% light	0.5 s
Colour consistency	<6	Power Factor (Fraction)	0.9
Colour rendering index (CRI)	90		

MASTER Value Glass LED bulbs

Voltage (nom.)	220-240 V
Temperature	
T-Case maximum (nom.)	70 °C
Controls and dimming	
Dimmable	Yes
Mechanical and housing	
Lamp Finish	Frosted
Bulb shape	A60 [A 60 mm]
Approval and application	
Energy Efficiency Class	D
Energy consumption kWh/1,000 hours	11 kWh
EPREL registration number	453261



EU RoHS compliant	Yes
Product data	
Full EOC	871951432503601
Order product name	MASVLE LEDBulbD10.5-100W B22A60 927FRGUK
Order code	32503601
SAP numerator – quantity per pack	1
Numerator – packs per outer box	10
Material number (12NC)	929003011899
Full product name	MASTERVLE LEDBulbD10.5-100W B22A60 927FRGUK
EAN/UPC - Case	8719514405288

Dimensional drawing

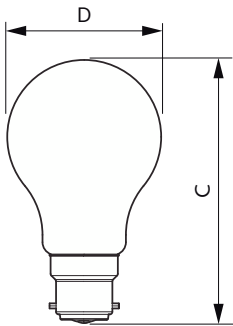

Product	D	C
MASVLE LEDBulbD10.5-100W B22A60 927FRGUK	60 mm	107 mm

Photometric data

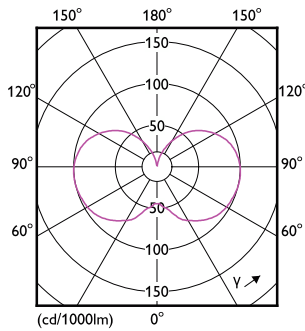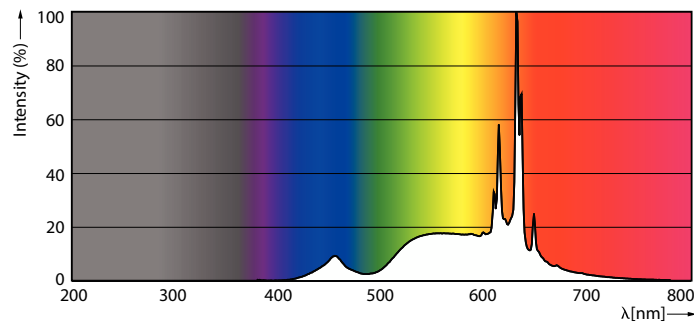


Spectral Power Distribution Colour - MASVLE LEDBulbD10.5-100W B22A60 927FRGUK

Light Distribution Diagram - MASVLE LEDBulbD10.5-100W B22A60 927FRGUK

MASTER Value Glass LED bulbs

Photometric data

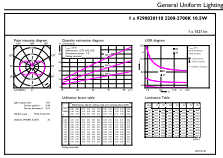

General uniform lighting - MASVLE LEDBulbD10.5-100W B22A60
927FRGUK

Lifetime



Life Expectancy Diagram - MASVLE LEDBulbD10.5-100W B22A60
927FRGUK



Lumen Maintenance Diagram - MASVLE LEDBulbD10.5-100W B22A60
927FRGUK

